




eMMC

KLMDG4UCTB-B041

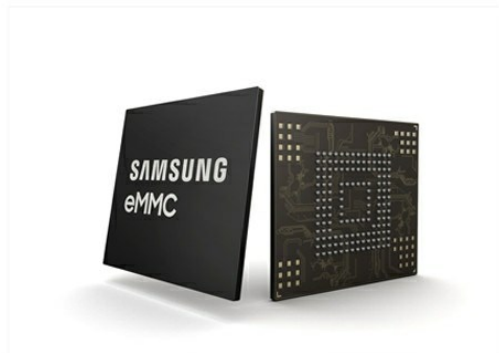

Overview

Specifications

Related resources

Related insights

# Definitive performance for mobile storage

With superior power efficiency and noticeably fast speed, Samsung's eMMC is the definitive choice for flash storage to develop slim mobile design.

## Specifications

Version	eMMC 5.1	Density	128 GB
Voltage	1.8 / 3.3 V	Interface	HS400
Package Size	11.5 x 13 x 1.0 mm	Temp.	-25 ~ 85 °C
Product Status	Sample		

[SEE ALL](#)


## Related insights



## Samsung's UFS 3.1: Flash Storage for the 5G Future

Samsung's UFS 3.1 will enable the smartphones of tomorrow to reach new levels of speed, and help pave the way for a new era of exciting mobile experiences.

[LEARN MORE >](#)

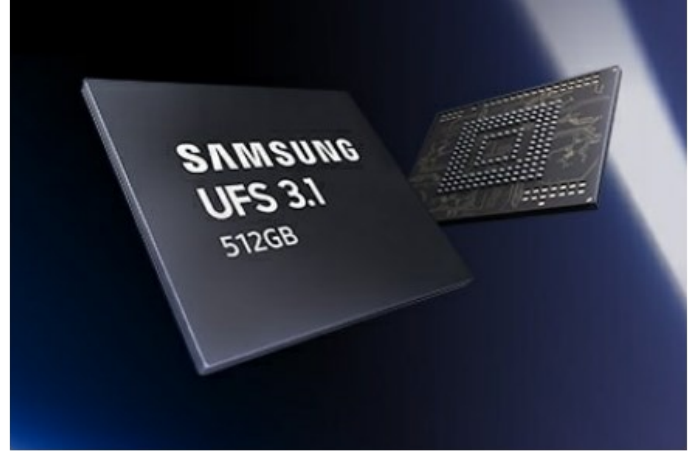

## Samsung Begins Mass Production of the Fastest Storage for Flagship

Samsung's new UFS 3.1 breaks the 1GB/s performance threshold in smartphone storage.

[LEARN MORE >](#)



All product specifications reflect internal test results and are subject to variations by user's system configuration. All product images shown are for illustration purposes only and may not be an exact representation of the product. Samsung reserves the right to change product images and specifications at any time without notice.

### Newsroom

#### Product finder

#### Technical resources

#### TCO calculator

#### About us

### PRODUCTS

DRAM

SSD

eSTORAGE

MCP

PROCESSOR

IMAGE SENSOR

SECURITY  
SOLUTIONS

DISPLAY IC

POWER IC

### SOLUTIONS

APPLICATIONS

TOPICS

TECHNOLOGY

### Other Sites

[中文\(简体\)](#)

[B2B Workplace](#)

[Memory \(日本語\)](#)

[ISOCELL](#)

[Exynos](#)


[LED](#)

[Display](#)

[Worker Safety](#)

[Samsung Business](#)

### Follow us

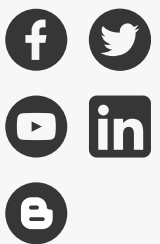

Copyright © 1995-2020 SAMSUNG All Rights Reserved.

[PRIVACY](#)

[LEGAL](#)

[SITEMAP](#)

This website is best viewed using Microsoft Internet Explorer 9 or higher, and/or latest version of Google Chrome and Mozilla Firefox browsers.