




+ CONNECTORS

RACK & PANEL CONNECTORS

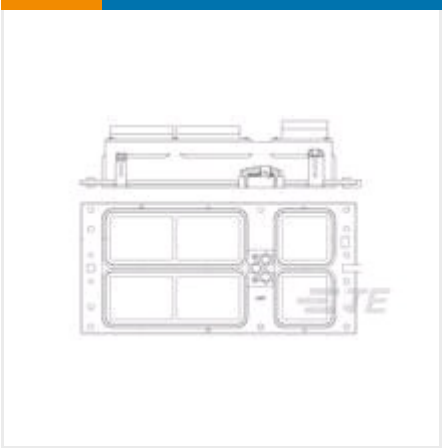

✓ Active

TE CONNECTIVITY (TE)
A600R,Sz3,Q11/Q11/blnk/Q11/Q11/85

AMP | ARINC 600 Series , Blank

2101423-1
TE Internal Number: 2101423-1

Not EU RoHS Compliant
Not EU ELV Compliant

Connector Style Receptacle

Preloaded Yes

Shell Size 3

Sealable No

Clinch Nuts With

↓ PRODUCT DRAWING
English

↓ 3D PDF

DOCUMENTATION

Product Drawings

RCPT ASSY,SIZE 3,ARINC 600 (11Q11/11Q11/BLANK/11Q11/11Q11/85)

PDF

English

CAD Files

3D PDF

PDF

3D

Customer View Model

2D_DXF.ZIP

English

Customer View Model

3D_IGS.ZIP

English

Customer View Model

3D_STP.ZIP

English

FEATURES



Please review product documents or [contact us](#) for the latest agency approval information.

Please Note: Use the Product Drawing for all design activity.

Product Type Features

Connector Style Receptacle
Shell Size 3
Sealable No
Product Type Connector

Configuration Features

Preloaded Yes
Keying 27
Release Style Front

Body Features

Shell Plating Material Aluminum
Shell Finish Chemical Conversion Coating

Contact Features

Contact Style Quadrax
Contact Type (Module B) Socket
Contact Arrangement (Module E) Q11
Contact Arrangement (Module F) 85
Contact Arrangement (Module B) Q11
Contact Size 16, 20, 22, 8
Contact Type (Module C) Socket
Contact Arrangement (Module A) Q11
Contact Type Pin, Socket
Contact Type (Module A) Socket
Contact Type (Module D) Socket
Contact Arrangement (Module D) Q11
Contact Arrangement (Module C) Blank (Dummy)

Mechanical Attachment

Hardware Type Head Cap Screw
Clinch Nuts With
Polarized Yes
Clinch Nut Size 11841

Other

Comment See drawing for additional product information.

PRODUCT COMPLIANCE



Statement of Compliance

Statement of Compliance

PDF