
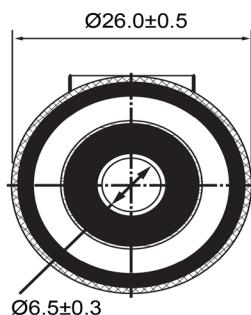
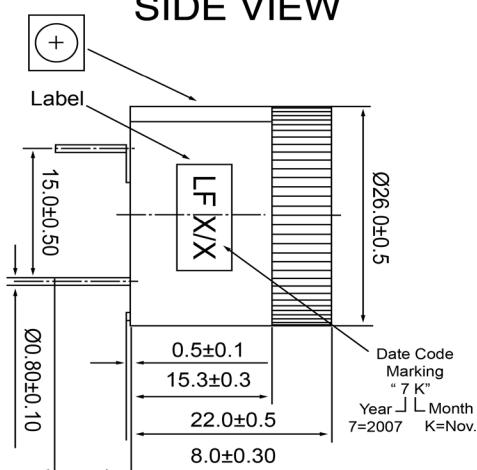


**TOP VIEW****SIDE VIEW****BOTTOM VIEW****Specifications**

Description	Value	Unit
Technology	Piezo	
Resonant Frequency	2,800	(Hz)
Rated Voltage	9 or 12	(V)
SPL @ 10cm	108	(dBA)
Tone	Single	
Mount Type	Thru-hole	
Voltage Range	5 ~ 18	(V)
Max Rated Current	50	(mA)
Housing Material	PBT	
Operating Temperature	-20 ~ +70	°C
Storage Temperature	-20 ~ +70	°C
Weight	15	(g)

**Notes**

1) All dimensions are in mm unless otherwise noted  
2) All parts meet RoHS

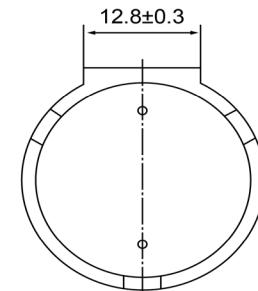

DB UNLIMITED

Piezo Indicator

Version	Description		Date	Approved
1	Released from Engineering		10/21/2013	J.S
Drawn by	Date	Checked by	Date	Approved by
A.B.	10/21/2013	C.E.	10/21/2013	J.S
				10/21/2013

IP262809-1