


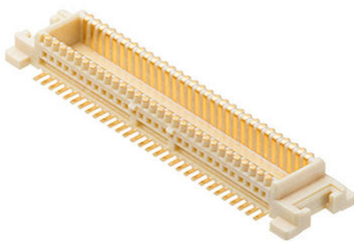

Part Number : [537480808](#)
Product Description : 0.50mm Pitch SlimStack Plug,
Surface Mount, Dual Row, Vertical, 3.00mm Stack
Height, 80 Circuits, without Vacuum Pick-up Tape
Series Number : 53748
Status : Active
Product Category : Board-to-Board Connectors



Documents and Resources

Drawings

[537480808 sd.pdf](#)

3D Models and Design Files

[STEP AP242](#)

[SOLIDWORKS](#)

[Creo](#)

[Symbol and Footprint \(Multi-Format\)](#)

Specifications

[SPK-53748-001-001.pdf](#)

[529910001-PS-000.pdf](#)

[PS-52991-003-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Compliant with Exemption 33; 44
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2025)7771-DC (04 Feb 2026)
EU RoHS	Compliant per EU 2015/863

[Compliance Statements](#)

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	Board-to-Board Connectors
Series	0.5, BB H3/4
Description	0.50mm Pitch SlimStack Plug, Surface Mount, Dual Row, Vertical, 3.00mm Stack Height, 80 Circuits, without Vacuum Pick-up Tape
Application	Board-to-Board, Signal
Component Type	PCB Header, Plug
Product Name	SlimStack
UPC	800754359634

Electrical

Current - Maximum per Contact	0.5A
Voltage - Maximum	50V

Physical

Breakaway	No
Circuits (Loaded)	80
Circuits (maximum)	80

First Mate / Last Break	No
Glow-Wire Capable	No
Guide to Mating Part	No
Keying to Mating Part	No
Lock to Mating Part	No
Mated Height	3.00mm
Mated Width	5.40mm
Material - Metal	Brass
Material - Plating Mating	Gold
Material - Plating Termination	Gold
Net Weight	190.658/mg
Number of Rows	2
Orientation	Vertical
Packaging Type	Embossed Tape on Reel
PCB Locator	No
PCB Retention	No
Pitch - Mating Interface	0.50mm
Plating min - Mating	0.100µm
Polarized to PCB	No
Shrouded	Fully
Temperature Range - Operating	-40° to +105°C
Termination Interface Style	Surface Mount

Mates With / Use With

Mates with Part(s)

Description	Part Number
0.50mm Pitch Vertical SlimStack Receptacles	<u>52991</u>
0.50mm Pitch Vertical SlimStack Receptacles	<u>54167</u>

This document was generated on Apr 11, 2026