

**Mallory Sonalert Products, Inc.**

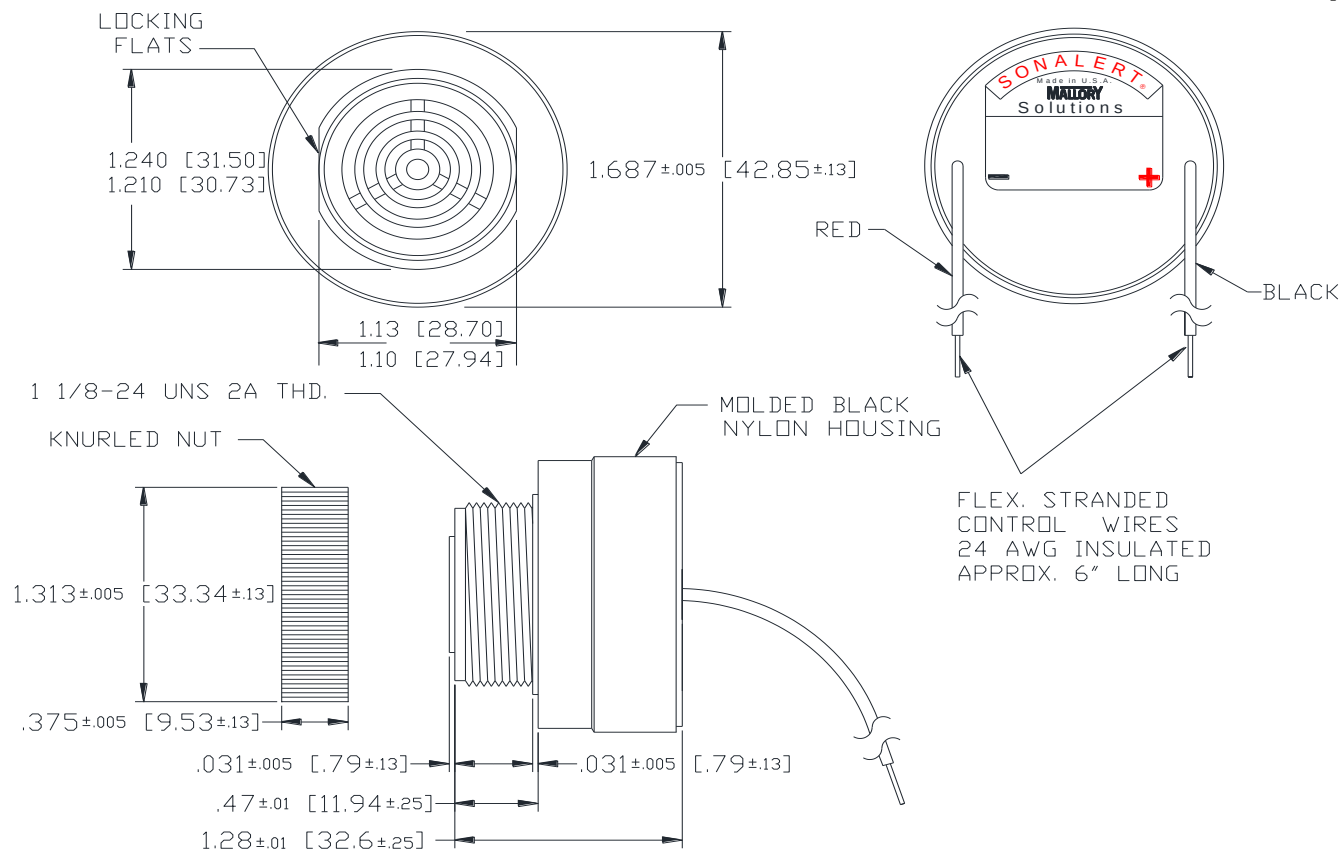
Part #:

**SCE120LA3CTW****Sales Outline Drawing**

Revision:

**C****Specifications:**

|                       |                                                                                            |
|-----------------------|--------------------------------------------------------------------------------------------|
| Sound Level Category  | Loud                                                                                       |
| Mode of Operation     | Continuous                                                                                 |
| Voltage Rating        | 48 to 120 VAC                                                                              |
| Frequency             | 2900 ± 500 Hz                                                                              |
| Loudness @ 2 FT       | 85 to 95 dB(A) Typ.                                                                        |
| Current Draw          | 40mA MAX                                                                                   |
| Housing Material      | 6/6 Nylon, Color: Black                                                                    |
| Storage Temperature   | -40° to +85° C                                                                             |
| Operating Temperature | -40° to +85° C                                                                             |
| Panel Mounting        | Recommended hole size is 1.25"(31.75mm). Thread front will fit standard 30mm(1.181") hole. |
| Knurled Nut           | Used to attach part to panel. The max recommended torque is 10 in-lbs.                     |
| Weight (Typical)      | 1.6 oz (45g)                                                                               |
| NEMA 3R,4X, & 12      | Approved with use of ACC03.                                                                |
| cUL Recognition       | cUL Recognized                                                                             |
| Options               | Please contact factory.                                                                    |

**Dimensions:** Inches (mm)**cUL Recognized****ROHS Compliant**

NOTE: MOUNTING- REMOVE BLACK PLASTIC NUT AND INSERT THREADED FRONT THROUGH 1.25" HOLE PUNCHED IN PANEL, IF ORIENTATION IS NEEDED, NOTE LOCKING FLATS ON DRAWING. SCREW NUT BACK ON. DO NOT OVERTIGHTEN.