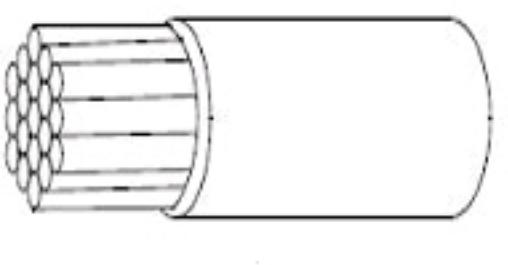


22759/32-26-1 Product Details

[!\[\]\(e3f8612927870f2e0f9f5989e6dd3064_img.jpg\) Share](#) [!\[\]\(a86c7d1c9cb81c81614634a31267440d_img.jpg\) Print](#) [!\[\]\(ce158fc5e55633398941d0898ae45661_img.jpg\) Email](#)

Spec 44, Spec 55 and Spec RCW Wire and Cable

[Always EU RoHS/ELV Compliant \(Statement of Compliance\)](#)

22759/32-26-1

TE Internal Number: 577596-000

[Obsolete](#)[Contact Product Information Center](#)[View all Features](#)[Add to My Part List](#)[Request Sample](#)[Find Similar Products](#)[Buy Product](#)**Quick Links**

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

Documentation & Additional Information**Product Drawings:**

- None Available

Related Products:

- [Tooling](#)

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- None Available

Application Specifications:

- None Available

Instruction Sheets:

- None Available

CAD Files:

- None Available

[List all Documents](#)**Product Features (Please use the Product Drawing for all design activity)****Product Type Features:**

- [Cable Type](#) = Spec 55
- [Cable Style](#) = Primary
- Number of Conductors = 1

Conditions for Usage:

- Temperature Range (°C) = -65 – +150
- Wire Size - Details = 26 AWG 0.15 mm², 0.00024 in², 19 x 38 AWG

Electrical Characteristics:

- Voltage Rating (VAC) = 600

Operation/Application:

- Application = General Purpose - Lightweight

Body Features:

- Wire Size (AWG/CM) = 26 AWG
- Conductor Type = Tin-Plated Copper
- Wire Color = Brown
- Nominal Outside Diameter (mm [in]) = 0.81 [0.032]
- Wire Diameter (mm [in]) = 0.81 [0.032]
- Conductor O.D. (mm [in]) = 0.50 [0.020]

Packaging Features:

- Wire Source = United States

Industry Standards:

- Government/Industry Qualification = Yes
- Government/Industry Part Number = M22759/32-26-1
- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

Other:

- Brand = Raychem

Corporate Information[Who We Are](#)[Investors](#)[News Room](#)[Supplier Portal](#)[Careers](#)**Quick Links**[Check Distributor Inventory](#)[Cross Reference](#)[Find Documents & Drawings](#)[Product Compliance Support Center](#)[Site Map](#)**Customer Support**[Email or Chat With Us](#)[Find a Phone Number](#)[Search Knowledge Base](#)[Manage your Account](#)**Keep Me Informed**

Receive TE News, Events & Technology Updates

Enter your email address Provide Website Feedback 