


Data Sheet | Item Number: 756-3106/040-030

Power cable; M12A socket; angled; M12A plug; angled; 4-pole; Length: 3 m


<https://www.wago.com/756-3106/040-030>

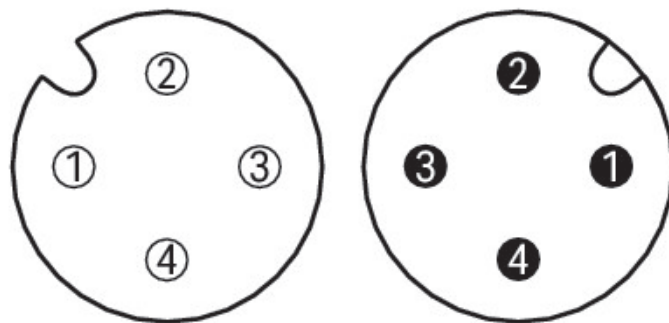

Pin 1 ... 4: 0.75 mm²

Diagram showing four horizontal lines representing different colors: brown, white, blue, and black. Each line is numbered 1 to 4 on both ends.

Line Number	Color
1	brown
2	white
3	blue
4	black

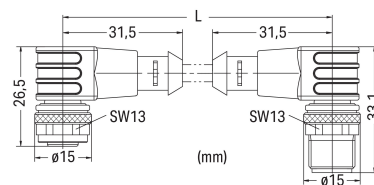

Dimensions in mm

Short description:

- PUR, halogen-free
- UL / CSA
- Suitable for drag chains
- Silicon- and CFC-free
- High resistance to microbes, hydrolysis, oil, chemicals and UV radiation
- High chemical resistance
- Cable used: UL listed

Technical data

Operating voltage	250 VAC/DC
Insulation resistance	$>10^9 \Omega$
Conductor resistance	$\leq 26 \Omega/\text{km}$

PU (SPU)	1 pcs
Packaging type	Box
Country of origin	DE
GTIN	4055143292078
Customs tariff number	85444290900
End of Sale	2024-05-01
End of Production	2024-05-15
End of Delivery	2024-06-01
End of Service and Repair	2025-06-01

UNSPSC	26121629
eCl@ss 10.0	27-06-18-01
eCl@ss 9.0	27-06-18-01
ETIM 9.0	EC001855
ECCN	NO US CLASSIFICATION

General approvals



Approval	Standard	Certificate Name
UL Underwriters Laboratories Inc.	UL 2238	E519602

Environmental Product Compliance	
Compliance Search	
Environmental Product Compliance 756-3106/040-030	



Documentation

System Description		
I/O-SYSTEM – SPEED-WAY, General Product Information	pdf 1035.20 KB	

Subject to changes. Please also observe the further product documentation!

Current addresses can be found at: www.wago.com