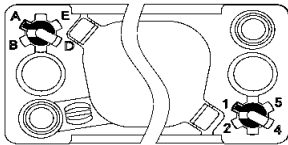
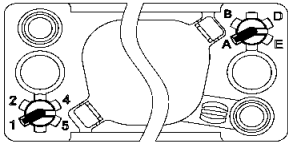
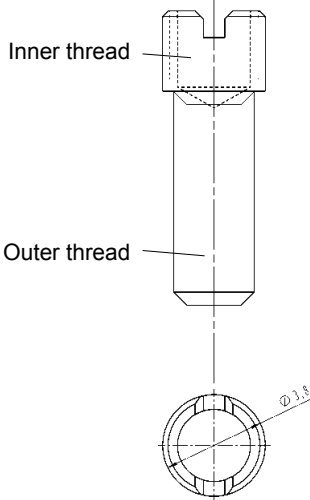
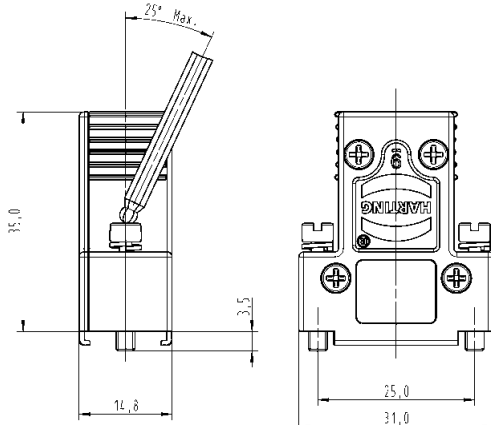


Accessories – coding system

Identification	Part number	Panel thickness	Dimensions in mm																																			
Coding¹⁾ Female 09 67 002 9121 xx 1 09 67 002 9121 xx 2 09 67 002 9121 xx 3 09 67 002 9121 xx 4 Male 09 67 002 9122 xx 1 09 67 002 9122 xx 2 09 67 002 9122 xx 3 09 67 002 9122 xx 4 Insert digits for coding configuration, e. g. "C3"		2.40 - 2.60 mm³⁾ 2.00 - 2.40 mm 1.20 - 2.00 mm 0.80 - 1.20 mm   36 coding configurations²⁾<table><tr><td>A1</td><td>B1</td><td>C1</td><td>D1</td><td>E1</td><td>F1</td></tr><tr><td>A2</td><td>B2</td><td>C2</td><td>D2</td><td>E2</td><td>F2</td></tr><tr><td>A3</td><td>B3</td><td>C3</td><td>D3</td><td>E3</td><td>F3</td></tr><tr><td>A4</td><td>B4</td><td>C4</td><td>D4</td><td>E4</td><td>F4</td></tr><tr><td>A5</td><td>B5</td><td>C5</td><td>D5</td><td>E5</td><td>F5</td></tr><tr><td>A6</td><td>B6</td><td>D6</td><td>E6</td><td>F6</td><td></td></tr></table>	A1	B1	C1	D1	E1	F1	A2	B2	C2	D2	E2	F2	A3	B3	C3	D3	E3	F3	A4	B4	C4	D4	E4	F4	A5	B5	C5	D5	E5	F5	A6	B6	D6	E6	F6	
A1	B1	C1	D1	E1	F1																																	
A2	B2	C2	D2	E2	F2																																	
A3	B3	C3	D3	E3	F3																																	
A4	B4	C4	D4	E4	F4																																	
A5	B5	C5	D5	E5	F5																																	
A6	B6	D6	E6	F6																																		
Depending on the panel thickness the suitable coding needs to be selected.																																						
Female screw lock for angled PCB connectors³⁾ <table><tr><th colspan="2">Thread</th></tr><tr><td>inner</td><td>outer</td></tr><tr><td>4 - 40 UNC</td><td>4 - 40 UNC</td></tr><tr><td>4 - 40 UNC</td><td>M3</td></tr><tr><td>M3</td><td>4 - 40 UNC</td></tr><tr><td>M3</td><td>M3</td></tr></table><table><tr><td>4 - 40 UNC</td><td>4 - 40 UNC</td></tr><tr><td>4 - 40 UNC</td><td>M3</td></tr><tr><td>M3</td><td>4 - 40 UNC</td></tr><tr><td>M3</td><td>M3</td></tr></table><table><tr><td>4 - 40 UNC</td><td>4 - 40 UNC</td></tr><tr><td>4 - 40 UNC</td><td>M3</td></tr><tr><td>M3</td><td>4 - 40 UNC</td></tr><tr><td>M3</td><td>M3</td></tr></table>	Thread		inner	outer	4 - 40 UNC	4 - 40 UNC	4 - 40 UNC	M3	M3	4 - 40 UNC	M3	M3	4 - 40 UNC	4 - 40 UNC	4 - 40 UNC	M3	M3	4 - 40 UNC	M3	M3	4 - 40 UNC	4 - 40 UNC	4 - 40 UNC	M3	M3	4 - 40 UNC	M3	M3	09 67 002 9123⁴⁾ 09 67 002 9124 09 67 002 9125 09 67 002 9126 09 67 002 9129 09 67 002 9130 09 67 002 9131 09 67 002 9132 09 67 002 9133 09 67 002 9134 09 67 002 9135 09 67 002 9136	2.00 - 2.60 mm 1.20 - 2.00 mm 0.80 - 1.20 mm Inner thread Outer thread 								
Thread																																						
inner	outer																																					
4 - 40 UNC	4 - 40 UNC																																					
4 - 40 UNC	M3																																					
M3	4 - 40 UNC																																					
M3	M3																																					
4 - 40 UNC	4 - 40 UNC																																					
4 - 40 UNC	M3																																					
M3	4 - 40 UNC																																					
M3	M3																																					
4 - 40 UNC	4 - 40 UNC																																					
4 - 40 UNC	M3																																					
M3	4 - 40 UNC																																					
M3	M3																																					
9 pole InduCom top entry hood for coding Please insert digit for screw option Hexagonal screw, thread M3 with captive washer Hexagonal screw, thread 4-40 UNC with captive washer	61 03 001 . 010 123																																					

1) MOQ = 50 pieces

2) Stock items (standard versions) in bold type

3) Female screw lock for straight PCB connectors on request

4) Standard versions