


P.C. solder pin angled with threaded mounting brackets
.370

Directive 2002/95/EC
"RoHS"
Compliant

(click on the schematic(s) for a more detailed view)

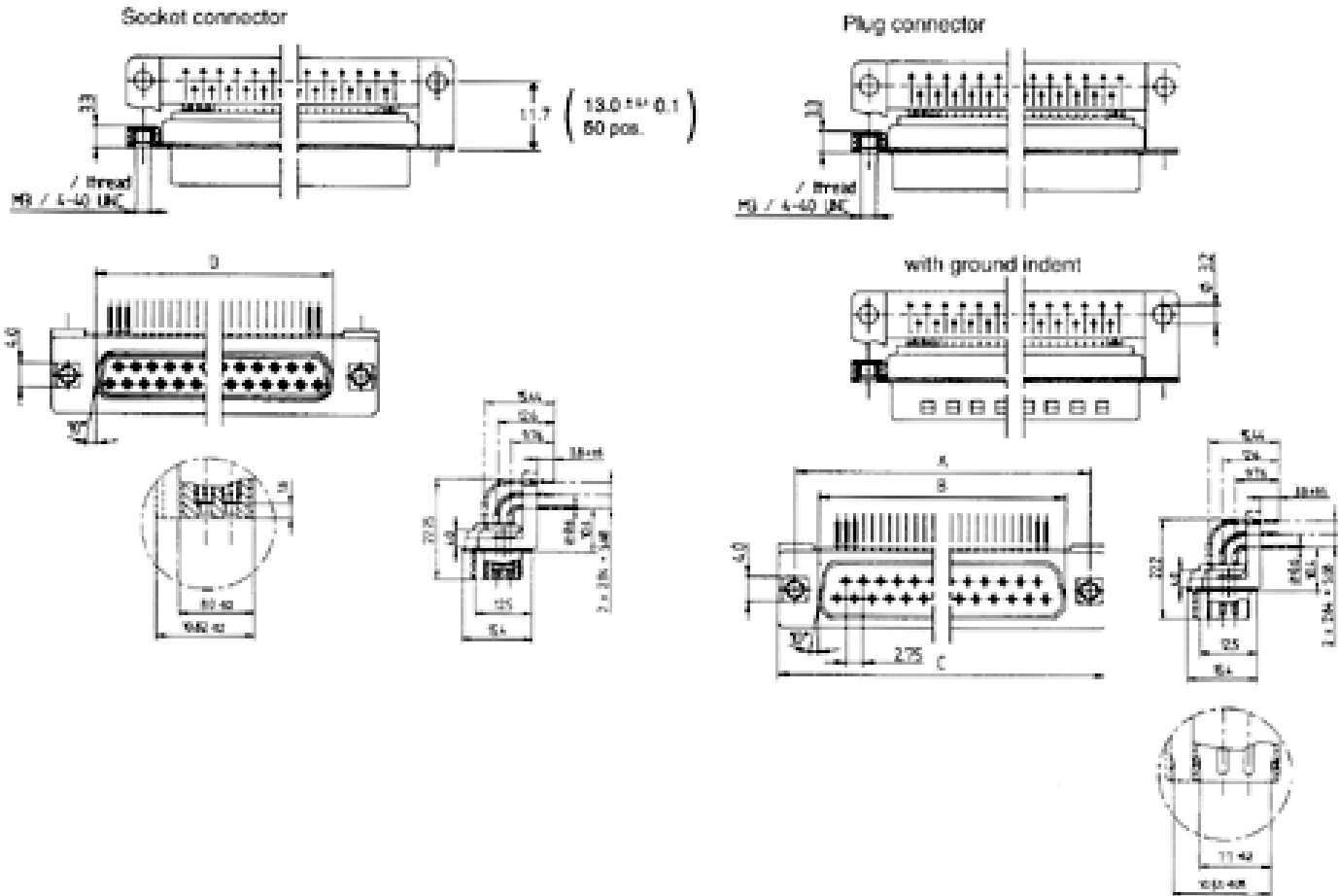

Socket connector:

No. of pos.	A - 0,76	B- 0,25	C
9	31,19	16,46	25,00 ^{+0,12} _{-0,13}
15	39,52	24,79	33,30 ^{+0,15} _{-0,10}
25	53,42	38,50	47,04 ^{±0,13}
37	69,70	54,96	63,50 ^{±0,13}
50	67,31	52,55	61,10 ^{+0,14} _{-0,11}

Plug connector:

No. of pos.	A - 0,76	B+0,25	C	D - 0,30
9	31,19	16,79	25,00 ^{+0,12} _{-0,13}	6,12
15	39,52	25,12	33,30 ^{+0,15} _{-0,10}	6,12
25	53,42	38,84	47,04 ^{±0,13}	5,99
37	69,70	55,30	63,50 ^{±0,13}	5,99
50	67,31	52,68	61,10 ^{+0,14} _{-0,11}	5,99

Part Numbers

No.of Pos.	Socket connector tin - plated	
	UNC 4 - 40	M 3
9	164 A 10719 X	164 A 10769 X
15	164 A 10729 X	164 A 10779 X
25	164 A 10739 X	164 A 10789 X
37	164 A 10749 X	164 A 10799 X
50	164 A 10759 X	164 A 10809 X

No.of Pos.	Plug connector tin - plated with ground indent	
	UNC 4 - 40	M 3
9	163 A 11769 X	163 A 11819 X
15	163 A 11779 X	163 A 11829 X
25	163 A 11789 X	163 A 11839 X
37	163 A 11799 X	163 A 11849 X
50	163 A 11809 X	163 A 11859 X