



COMPACT 4G LTE
M2M ROUTER



DIGI TRANSPORT® WR11 XT

Secure 3G/4G/LTE cellular router for retail, kiosk and industrial control applications

Digi TransPort WR11 XT delivers a cost-optimized 4G LTE connection to mission critical M2M applications around the world. These cellular routers are ideal for connecting:

- Building and process automation controllers
- Smart grid assets (meters, switches and controllers)
- IP cameras and access controllers
- Remote data loggers, flow meters and sensing equipment
- Telco infrastructure controllers
- ATMs, kiosks and service terminals



The Digi TransPort WR11 XT provides a secure, reliable connection to industrial controllers, retail terminals and process automation equipment on third party sites or remote locations. This drop-in connectivity gives operators a way to reduce the cost of downtime and service calls and also increase revenue by bringing distributed sites online faster.

Digi management solutions provide easy setup, configuration and maintenance of large installations of remote Digi TransPort devices. Digi Remote Manager® offers web-based device management for remote Digi cellular routers, gateways and third-party devices.

BENEFITS:

- Global HSPA+ and 4G LTE support and certification
- Extremely resilient cellular connection through patented Digi SureLink™, VRRP+ protocol and dual SIM slots
- Enterprise routing features for security, logging and redundancy (e.g., stateful firewall, VPN, SNMP); no annual enterprise software license required
- Digi Remote Manager provides mass configuration, device management and troubleshooting tools
- Rugged aluminum enclosure, flanges and optional DIN rail clip for flexible mounting
- 5-year warranty standard—no additional cost

APPLICATION EXAMPLE

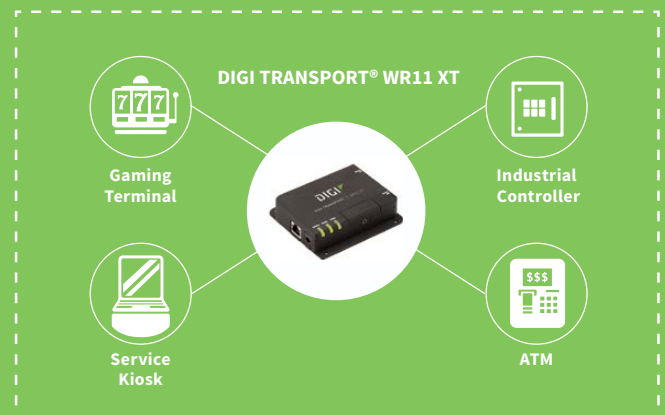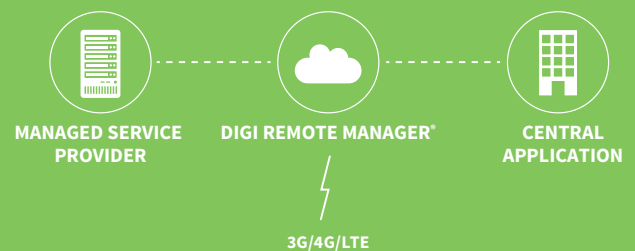

RELATED PRODUCTS



 
Digi TransPort®
WR21



Digi TransPort®
WR31



Digi TransPort®
WR44 R




Accessories



Digi Remote
Manager®


SPECIFICATIONS		Digi TransPort® WR11 XT	
CELLULAR			
LTE - EMEA (M3)		LTE CAT 1: 800(B20)/900(B8)/1800(B3)/2100(B1)/2600 (B7) 2G EDGE: 900/1800 MHz Transfer rate (max): 10 Mbps down, 5 Mbps up	
LTE - UNITED STATES (M4)		LTE CAT 1: 700(B12)/850(B5,B26)/AWS(B4)/1900(B2,B25) Transfer rate (max): 10 Mbps down, 5 Mbps up Approvals: Sprint (pending)	
LTE - NORTH AMERICA (M6)		LTE CAT 1: 700(B12,B13)/850(B5)/AWS(B4)/1900(B2) HSPA+: 850/1900 MHz Transfer rate (max): 10 Mbps down, 5 Mbps up Approvals: PTCRB, AT&T, Verizon, Telus (pending)	
LTE - ANZ/LATAM (M9)		LTE CAT 1: 700(B28)/850(B5)/900(B8)/1800(B3)/2100(B1) 3G HSPA+: 850/900/2100 MHz Transfer rate (max): 10 Mbps down, 5 Mbps up	
GLOBAL HSPA+ - (U9)		3G HSPA+: 850/900/1700AWS/1900/2100 MHz 2G EDGE/GPRS: 850/900/1800/1900 MHz Transfer rate (max): 21 Mbps down, 5.76 Mbps up Approvals: PTCRB, Vodafone	
CONNECTORS		(2) 50 Ω SMA (center pin: female); (1) connector for non-LTE models	
SIM SLOTS		(2) Mini-SIM (2FF)	
SIM SECURITY		Screw-down SIM cover	
SOFTWARE & MANAGEMENT			
REMOTE MANAGEMENT		Digi Remote Manager® (cloud based); SNMP v1/v2c/v3 (user installed/managed)	
LOCAL MANAGEMENT		WebUI (HTTP/HTTPS); CLI (Telnet, SSH, SMS)	
MANAGEMENT/ TROUBLESHOOTING TOOLS		FTP, SFTP, SCP; Protocol analyzer with PCAP for Wireshark; Event logging with Syslog and SMTP; NTP/SNTP	
MEMORY		20 MB RAM, 10 MB file space	
ETHERNET			
PORTS		(1) RJ-45; 10/100 Mbps (auto-sensing)	
PHYSICAL			
DIMENSIONS (L X W X H)		3 in x 4 in x 1 in (7.62 cm x 10.16 cm x 2.54 cm)	
WEIGHT		0.5 lb (.22 kg)	
STATUS LEDS		Power on, WWAN signal strength, WWAN service	
ENCLOSURE		Industrial (Metal) / IP30	
POWER REQUIREMENTS			
POWER INPUT		5 VDC, 15W minimum power source required	
POWER SUPPLY		Must be used with a Digi approved power supply	
POWER CONSUMPTION		3.5W typical (Idle); 10W typical (Peak Tx/Rx)	
ENVIRONMENTAL			
OPERATING TEMPERATURE		-30° C to +70° C (-22° F to +158° F) reduced cellular performance may occur above +60° C	
RELATIVE HUMIDITY		5% to 95% (non-condensing)	
APPROVALS			
CELLULAR		PTCRB	
SAFETY		UL 60950, CSA 22.2 No. 60950, EN60950	
EMISSIONS/IMMUNITY		CE, FCC Part 15 Class B, AS/NZS CISPR 22, EN55024, EN55022 Class B	
WARRANTY			
PRODUCT WARRANTY		5 years	

DIGI TRANSPORT® WR11 XT - TOP

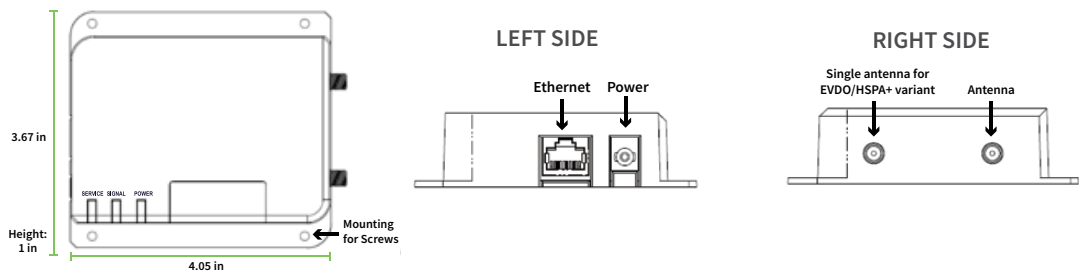

ENTERPRISE SOFTWARE	DESCRIPTION
PROTOCOL SUPPORT	HTTP, HTTPS, FTP, SFTP, SSL, SMTP, SNMP (v1/v2c/v3), SSH, Telnet and CLI for web management; Remote management via Digi Remote Manager; SMS management, protocol analyzer, ability to capture PCAP for use with Wireshark; DynDNS; Dynamic DNS client compatible with BIND9/No-IP/DynDNS
SECURITY/VPN	IP filtering, stateful inspection firewall with scripting, address and port translation; VPN: IPSec with IKEv1, IKEv2, NAT Traversal; SSL, SSLv2, SSLv3, FIPS 197, open VPN client and server; PPTP, L2TP;(5) VPN tunnels (not upgradable); Cryptology: SHA-1, MD5, RSA; Encryption: DES, 3DES and AES up to 256-bit (CBC mode for IPsec); Authentication: RADIUS, TACACS+, SCEP for X.509; certificates; Content filtering (via 3rd party); MAC address filtering; VLAN support
ROUTING/FAILOVER	IP pass-through; NAT, NAPT with IP port forwarding; Ethernet bridging; GRE; Multicast routing; Routing protocols: PPP, PPPoE, RIP (v1, v2) OSPF, SRI, BGP, iGMP routing (multicast); RSTP (Rapid Spanning Tree Protocol); IP failover: VRRP, VRRP+TM; Automatic failover/ failback to second GSM network/standby APN
OTHER PROTOCOLS	DHCP; Dynamic DNS client compatible with BIND9/No-IP/DynDNS; QoS via TOS/DSCP/WRED

DIGI REMOTE MANAGER®

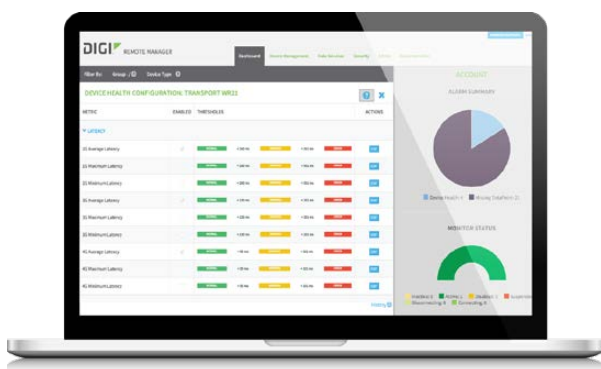

CAPABILITIES

- Centralized management of remote devices over 3G/4G/LTE
- Define standard configurations and automatically monitor individual devices for PCI security compliance
- Report and alert on performance statistics, including connection history, signal quality, latency, data usage and packet loss
- No servers or applications to operate and maintain
- Complete tasks for your entire device network in minutes
- Edit configurations and update firmware for your individual devices or groups
- Monitor the status and location of your remote device via a web browser
- Active or deactivate cellular lines and monitor data to ensure you never incur overage charges

INFRASTRUCTURE

- Hosted in a commercial-grade SAS 70-certified environment
- Superior availability, operating to 99.9% or greater
- Open APIs available to support application development

SECURITY

- Certified SSAE-16 facilities
- Over 175 Security Controls in place to protect your data
- Enables compliance with security frameworks like PCI, HIPAA, NIST and more
- Earned SkyHigh's Cloud Trust Program highest ranking of Enterprise-Ready

PART NUMBERS	DIGI TRANSPORT WR11 XT
WR11-M300-DE1-XB	Digi TransPort WR11 XT - 4G LTE EMEA/APAC, Single Ethernet
WR11-M600-DE1-XB	Digi TransPort WR11 XT - 4G LTE Sprint, Single Ethernet
WR11-M900-DE1-XB	Digi TransPort WR11 XT - 4G LTE North America, Single Ethernet
WR11-U900-DE1-XB	Digi TransPort WR11 XT - 4G LTE APAC/LATAM, Single Ethernet
WR11-U900-DE1-XB	Digi TransPort WR11 XT - HSPA+ Global, Single Ethernet
WR11-U900-DE1-XW	Digi TransPort WR11 XT - HSPA+ Global, Single Ethernet
WR11-L600-DE1-XU	Digi TransPort WR11 XT - 4G LTE North America, Single Ethernet
WR11-L700-DE1-XB	Digi TransPort WR11 XT - 4G LTE EMEA/APAC, Single Ethernet
WR11-L700-DE1-XW	Digi TransPort WR11 XT - 4G LTE EMEA/APAC, Single Ethernet
WR11-L800-DE1-XU	Digi TransPort WR11 XT - 4G LTE Verizon, Single Ethernet

PART NUMBERS	ACCESSORIES*
76000926	Antenna - Cellular, 3G/4G/LTE
76000954	Antenna Base – SMA, 1m, RG174
76002074	Accessory Kit - AC Power, Std Temperature, EU Plug
76002065	Accessory Kit - DC Power
76002062	Accessory Kit - AC Power, Std Temperature, US Plug
76002063	Accessory Kit - AC Power, Std Temperature, Intl Plugs
76002064	Accessory Kit - AC Power, Extd Temperature, Intl Plugs
76000935	AC Power Supply - EU Plug to 5VDC - 2.5mm locking barrel plug
76000965	AC Power Supply - Extd Temperature, Universal plugs (US, EU, UK, AU) to 5VDC - 2.5mm locking barrel plug
76000934	AC Power Supply - US Plug to 5VDC - 2.5mm locking barrel plug
76000976	DC Power Supply - Converts 9-30VDC to 5VDC - 2.5mm locking barrel plug
76002021	AC Power Supply - Std Temperature, Universal plugs (US, EU, UK, AU) to 5VDC - 2.5mm locking barrel plug
76000682	Mounting Bracket – DIN Rail
76000826	Cable - Ethernet, RJ45 to RJ45, 2m

*Sold separately, unless otherwise noted.

FOR MORE INFORMATION
PLEASE VISIT WWW.DIGI.COM

DIGI SERVICE AND SUPPORT / You can purchase with confidence knowing that Digi is always available to serve you with expert technical support and our industry leading warranty. For detailed information visit www.digi.com/support.

© 1996-2018 Digi International Inc. All rights reserved.
All trademarks are the property of their respective owners.

91004202
A6/818

DIGI INTERNATIONAL WORLDWIDE HQ
877-912-3444 / 952-912-3444 / www.digi.com

DIGI INTERNATIONAL GERMANY
+49-89-540-428-0

DIGI INTERNATIONAL JAPAN
+81-3-5428-0261 / www.digi-intl.co.jp

DIGI INTERNATIONAL SINGAPORE
+65-6213-5380

DIGI INTERNATIONAL CHINA
+86-21-50492199 / www.digi.com.cn

