




Part Number : [1510340022](#)

Product Description : 11.00mm Pitch EXTreme Guardian Receptacle TPA Clip, 2 Circuits

Series Number : 151034

Status : Active

Product Category : Connector Accessories

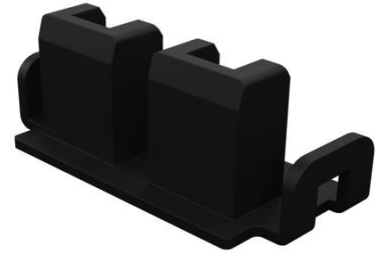

Documents and Resources

Drawings

[1510340022_sd.pdf](#)

[PK-151076-0001-001.pdf](#)

[STEP AP242](#)

[SOLIDWORKS](#)


[Creo](#)

Specifications

[PS-151053-0000-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2025)7771-DC (04 Feb 2026)
EU RoHS	Compliant per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	Connector Accessories
Series	151034
Description	11.00mm Pitch EXTreme Guardian Receptacle TPA Clip, 2 Circuits
Component Type	Terminal Position Assurance (TPA)
Product Name	EXTreme Guardian
UPC	887191678474

Agency

CSA	LR19980
UL	E29179

Physical

Circuits (Loaded)	2
Circuits (maximum)	2
Color - Resin	Black
Flammability	94V-0
Lock to Mating Part	Yes
Material - Resin	Polybutylene Terephthalate (PBT)
Net Weight	1.059/g
Number of Rows	1

Packaging Type	Tray
Temperature Range - Operating	-40° to +105°C

Solder Process Data

Lead-Free Process Capability	N/A
------------------------------	-----

This document was generated on May 14, 2026