

## Jumper Along 1x5 black 16A

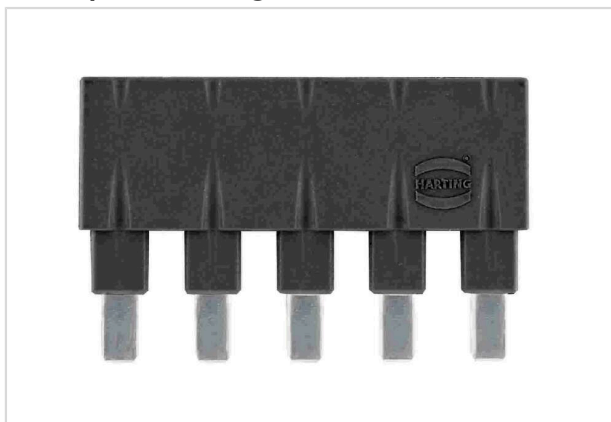


Image is for illustration purposes only. Please refer to product description.

Part number	09 33 000 9855
Specification	Jumper Along 1x5 black 16A
HARTING eCatalogue	<a href="https://harting.com/09330009855">https://harting.com/09330009855</a>

### Identification

Category	Accessories
Series	Han <sup>®</sup> ES Press
Type of accessory	Plug-in jumper
Description of the accessory	1x 5 Longitudinal

### Version

Details	When using plug-in jumpers within Han <sup>®</sup> ES Press hoods of high construction must be used.
---------	--

### Technical characteristics

Rated current	16 A
Rated voltage	500 V
Rated impulse voltage	6 kV
Pollution degree	3
Rated voltage acc. to UL	600 V
Insulation resistance	$>10^{10} \Omega$
Contact resistance	$\leq 1 \text{ m}\Omega$
Limiting temperature	-40 ... +125 °C
Mating cycles	$\geq 5$

### Material properties

Material (contacts)	Copper alloy
---------------------	--------------



Pushing Performance  
Since 1945

## Material properties

Surface (contacts)	Tin plated
Material (accessories)	Polyamide (PA)
Colour (accessories)	RAL 5004 (black blue)
Material flammability class acc. to UL 94	V-0
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
Fire protection on railway vehicles	EN 45545-2 (2020-08) + A1 (2023-10)
Requirement set with Hazard Levels	R22 (HL 1-3) R23 (HL 1-3)

## Commercial data

Packaging size	5
Net weight	3.8 g
Country of origin	China
European customs tariff number	85389099
GTIN	5713140192683
eCl@ss	27440292 Connector component (accessories)
ETIM	EC002943
UNSPSC 24.0	39121400