


LK-4N-F25

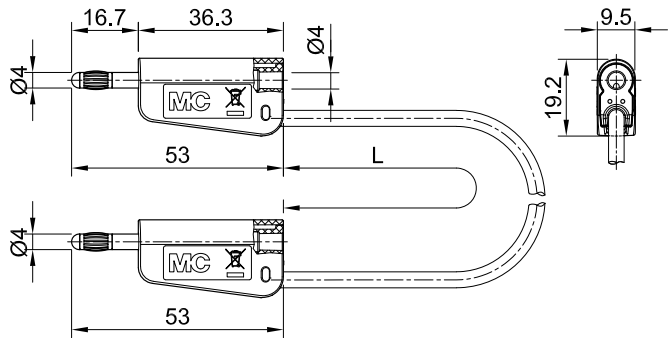

Item number 64.1034- *

Highly flexible, with stackable Ø 4 mm MULTILAM plugs on both ends.

Technical data	
Diameter of plug system	4 mm
Rated Values	30 V, 32 A / 60 V, 32 A
Surface treatment electrical contact	Ni
Base material electrical contact	CuZn
Standard color(s) *	20212223242526272829
Lead lengths	025; 050; 075; 100; 150; 200 cm
Lead insulation	PVC
Lead cross section	2,5 mm ²
Test accessory acc. to	IEC EN 61010-031
User-Information	I 099