


DIGITAST Series

Microminiature SPDT, Keyswitches

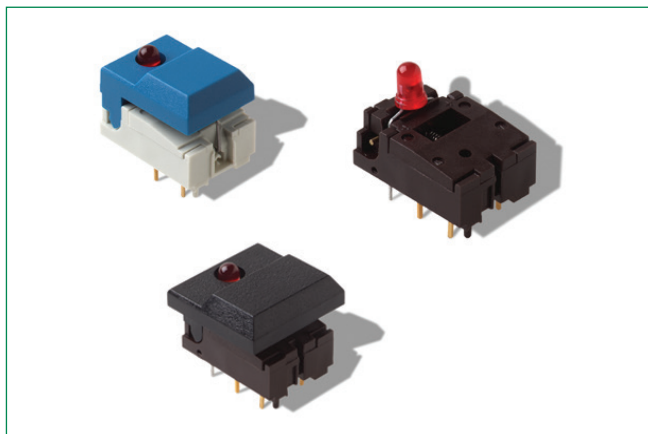

Specifications

Function	Momentary or push-push
Contact Arrangement	1 change over contact SPDT, NO
Mode of Switching	Non-shorting
Distance Between Button Centers	Horizontal Min.: 12.7 (0.500) or 17.78 (0.700) Vertical Min. 17.78 (0.700)
Terminals	PC pins
Mounting	Soldering, centering pins
Total Travel	≤ 3 (0.0018)
Switching Travel	1.5 (0.0591)
Latching Travel	1.8 (0.0709)
Operating Force	1.5 +/- 0.5 N (150 +/- 50 grams)
Solderability	Wave soldering, compatible with lead free soldering profile Hand soldering, 350°C for 3 seconds

Description

With Digitast Micro-miniature SPDT keyswitches from C&K, designers gain a reliable, low-level switching solution for their audio and lighting consoles, instrumentation and industrial electronics applications that comes ready to implement on a PCB. Available in momentary or push-push formats, Digitast keyswitches can also be delivered in a variety of different button options or with an optional latching function.

Features & Benefits

- High reliability/long life
- Designed for low level switching
- Ready to implement on PCB
- Latching function available
- Several button options
- RoHS compliant and compatible

Applications

- Medical
- Instrumentation
- Industrial electronics
- Audio electronics

Electrical Characteristics

Switching Power Max.	240 mW DC
Switching Voltage Max.	24 V DC
Switching Current Max.	10 mA DC
Carrying Current at 20°C (push-push version)	100 mA
Dielectric Strength (50 Hz, 1 min)	500 V
Operating Life with or Without Max. Switching Power	Momentary: ≥ 5 x 10 ⁶ operations Push-push: ≥ 5 x 10 ⁵ operations
Contact Resistance	Initial ≤ 50 mΩ After 5 x 10 ⁶ operations: ≤ 100 mΩ
Insulation Resistance	≥ 10 ¹⁰ Ω
Capacitance	At f = 10 kHz: ≤ 0.8 pF
Bounce Time	≤ 2.5 ms Operating speed 400 mm/s (15.75/s)
Operating Temperature	-25°C to 85°C

Ordering Number

Our easy build-a-switch concept allows you to mix and match options to create the switch you need. To order, select desired option from each category and place it in the appropriate box.

Switch

Reference
SER BK AU OA



XX - X - X - X - X - X - X - X - X - X									
Series									
SER: Narrow button									
SET: Wide button									
SERU: Switch body only (no button)									
LED									
None: No LED									
L: 1 LED									
2L: 2 LEDs									
Button Color ²									
None: (SERU)									
BK: Black									
GY: Gray									
WH: White									
RD: Red									
BU: Blue									
1st LED Color ³									
None: No LED									
RD: Red									
YE: Yellow									
GN: Green									
LED Spacing ¹									
None: Narrow LED Spacing (TYP Europe)									
7.62: Wide LED Spacing (TYP No. America)									
Body Color									
None: White (STD)									
BRN: Brown									
Function									
EE: Latching									
OA: Non-latching									
Contact Material									
Au: Gold									
2nd LED Color ³									
None: No LED									
RD: Red									
YE: Yellow									
GN: Green									

Notes:

1. Some of the configurations may not be available or could require some development.

DIGITAST Series

Microminiature SPDT, Keyswitches



Button

Reference
SRK BK



xx - K - x - x - x

Button Style
SR: Narrow
ST: Wide

LED Holes
None: No LED holes
L: 1 LED hole
2L: 2 LED holes


 


Button Color²
BK: Black
GY: Gray
WH: White
RD: Red
BU: Blue

Latching
None: For use with momentary switch
EE: Latching


1. LED spacing only applies when 1 LED requested
2. Additional button colors available by request
3. Additional LED colors available by request including Bi color configurations

Designation


SER Narrow Button

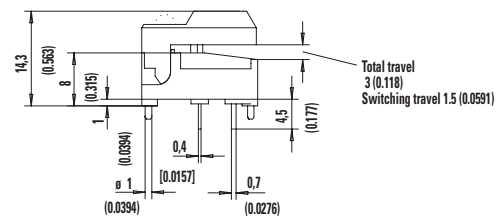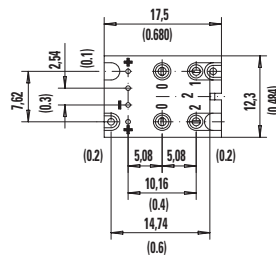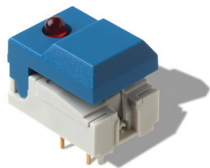


SER

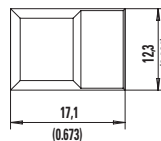





SERL

 


SER2L

 


SET Wide Button

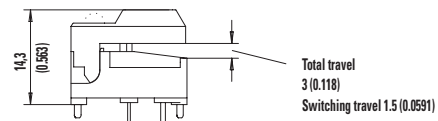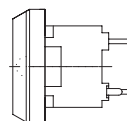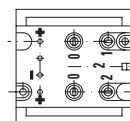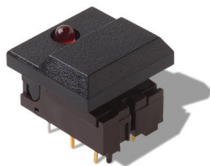


SET

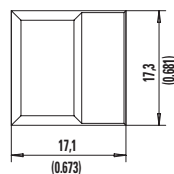

SETL

 

SET2L

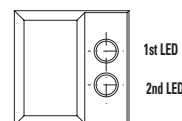


DIGITAST Series

Microminiature SPDT, Keyswitches




SERU No Button

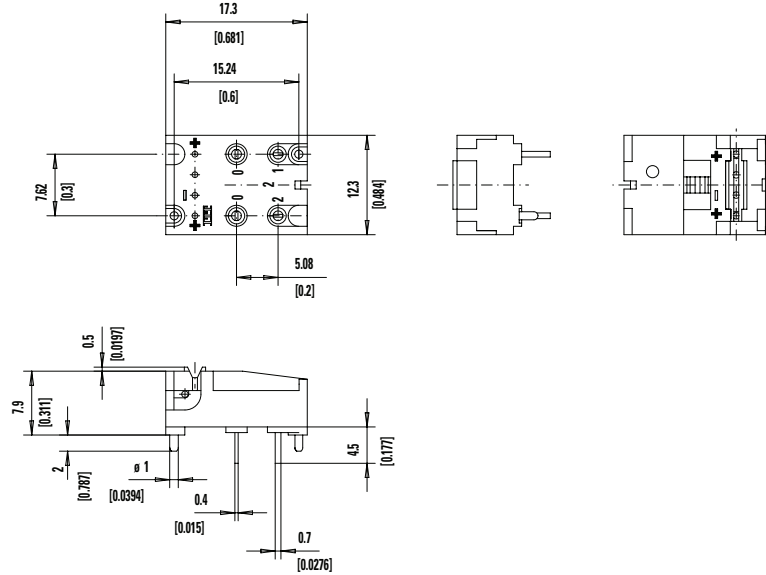


LED



None No LED

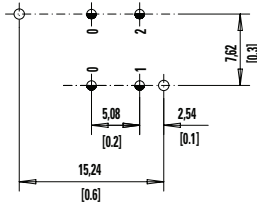

L 1 LEDs

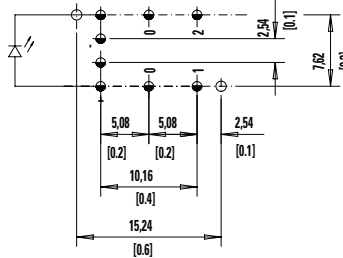

2L 2 LEDs

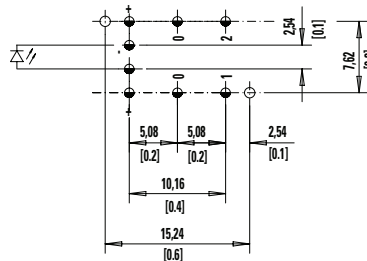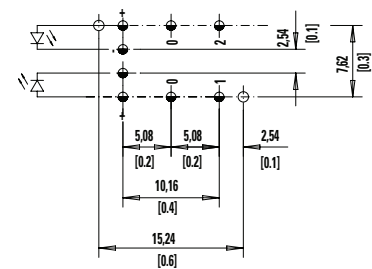

⌀ 1.0±0.1 (0.0394±0.00349)

⌀ 1.1±0.05 (0.0433±0.00197)

Button Color

BK Black

GY Gray

Other button colors available by request [red (RD), green (GN), white (WH), yellow (YE), blue (BU), orange (OG)].

DIGITAST Series

Microminiature SPDT, Keyswitches



LED Color

Option Code	Color
None	Models without LED
RD	Red
GN	Green
YE	Yellow

Contact Material

Option Code	Material
Au	Gold

Function

Option Code	Color	Schematic
OA	Momentary	
EE	Push-Push	

Disclaimer Notice - Information furnished is believed to be accurate and reliable. However, users should independently evaluate the suitability of and test each product selected for their own applications. Littelfuse products are not designed for, and may not be used in, all applications. Read complete Disclaimer Notice at <http://www.littelfuse.com/disclaimer-electronics>.