

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1210641239](#)
Status: **Active**
Overview: mPm DIN Valve Connectors
Description: mPm DIN Valve Connector, Form B, PG7 Internal Threads, 2 Pole Plus Ground with C4 Circuit, 24V, Yellow LED, Transparent, Nitrile Gasket, Bulk Pack Mounted

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Packaging Specification PK-121064-S62-001 \(PDF\)](#)

Agency Certification

UL E218123

General

Product Family Field Attachable / Accessories
Series [121064](#)
IP Rating IP65, IP67
Material - Contact Brass
Overview [mPm DIN Valve Connectors](#)
Product Name mPm
Type Field Attachable Connector
UPC 883906737832

Physical

Cable Diameter N/A
Coupling Type Internal Thread
Diagnostics / LEDs Yes
Diagnostics Port No
Gender N/A
Keyway None
Material - Connector Body Polypropylene
Material - Coupling Nut N/A
Material - Plating Mating Silver
Net Weight 18.860/g
Orientation 90° Angle
Pitch - Mating Interface 10.00mm
Poles 2
Temperature Range - Operating -40°C to +90°C
Wire Size AWG N/A

Electrical


Current - Maximum per Contact 16.0A
Voltage - Maximum 24V

Material Info

Engineering Number S62209TC4H1

Reference - Drawing Numbers

Packaging Specification PK-121064-S62-001
Sales Drawing SD-121064-004

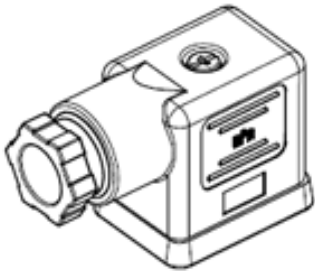

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Contained Per -
ED/71/2019 (16 July
2019)

Lead

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

[121064](#) Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION