

Connectors


Rectangular Connectors

Rectangular Contact Inserts

1-1195487-3

ACTIVE

Rectangular Contact Inserts, Contact Insert, Pin, Wire-to-Wire, 20 Position, Sealable, 20 – 26 AWG Wire Size, .5 – .14 mm² Wire Size, 1.5 A

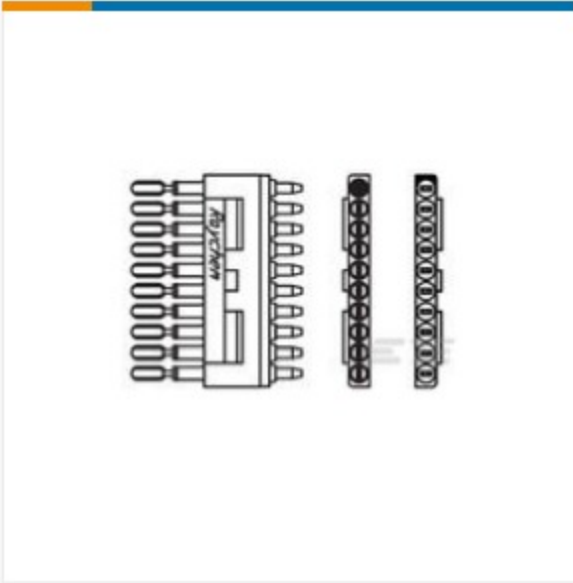

RAYCHEM

TE Internal #: 699316-000

TE Internal Description: MTC100-JA2-P11-T13

Rectangular Connector Insert Type : Contact Insert

Contact Type : Pin

Connector System : Wire-to-Wire

Number of Positions : 20

Centerline (Pitch) : 1.27 mm [.05 in]

Add to List

 |

Similar Products

 |

Download Digital Datasheet

Compatible Parts & Tooling

Documents	Features	Product Compliance
Please review product documents or contact us for the latest agency approval information. Please Note: Use the Product Drawing for all design activity.		
Product Type Features	Rectangular Connector Insert Type : Contact Insert Connector System : Wire-to-Wire Sealable : Yes Connector & Contact Terminates To : Wire & Cable	
Configuration Features	Number of Positions : 20	
Body Features	Primary Product Color : Black Primary Product Material : High Grade Polyarylene Thermoplastic Seal Type : Interfacial Seal	
Contact Features	Contact Type : Pin Contact Current Rating (Max) (A): 1.5	
Mechanical Attachment	Polarization Code : A Connector Mounting Type : Panel Mount	
Housing Features	Centerline (Pitch) : 1.27 mm [.05 in]	
Dimensions	Wire Size (AWG): 20 – 26 Wire Size (mm²): .5 – .14	
Usage Conditions	Operating Temperature Range : -65 – 125 °C [-85 – 257 °F]	
Operation/Application	Compatible With Connector Shell Size : 50.8 [2.0]	

SHOP OUR DISTRIBUTORS

No inventory is available in North America. Regions with inventory are shown below. For additional information, [contact us](#)

Europe

See all price breaks

Distributor110,000Buy

SG Connexion AB

in-stock

Visit Site

We are here to help!

Get in touch with our product experts.

CHAT WITH US

EMAIL US

CALL US

REPORT PRODUCT DATA ERROR

Compatible Parts

There are no compatible parts for this product.

Please reach out to Product Support to help with your request.

[Contact Product Support](#)

Products with Similar Specs

[View All Similar Products](#)

THIS PRODUCT

RECTANGULAR CONTACT INSERTS

1-1195487-3

Rectangular Contact Inserts, Contact Insert, Pin, Wire-to-Wire, 20 Position...

In-Stock

Rectangular Connector Insert Type : Contact Insert

Contact Type : Pin

Connector System : Wire-to-Wire

Number of Positions : 20

Centerline (Pitch) : 1.27 mm

TOP RESULTS

RECTANGULAR CONTACT INSERTS

697120-000

Rectangular Contact Inserts, Contact Insert, Pin, Wire-to-Wire, 20 Position...

Non-Stocked

Rectangular Connector Insert Type : Contact Insert

Contact Type : Pin

Connector System : Wire-to-Wire

Number of Positions : 20

Centerline (Pitch) : 1.27 mm

RECTANGULAR CONTACT INSERTS

MTC100-JA2-P31-T29

Rectangular Contact Inserts, Contact Insert, Pin, Wire-to-Wire, 20 Position...

Non-Stocked

Rectangular Connector Insert Type : Contact Insert

Contact Type : Pin

Connector System : Wire-to-Wire

Number of Positions : 20

Centerline (Pitch) : 1.27 mm

RECTANGULAR CONTACT INSERTS

697122-000

Rectangular Contact Inserts, Contact Insert, Pin, Wire-to-Wire, 20 Position...

Non-Stocked

Rectangular Connector Insert Type : Contact Insert

Contact Type : Pin

Connector System : Wire-to-Wire

Number of Positions : 20

Centerline (Pitch) : 1.27 mm

Customers Also Bought

TE Part #: NTFR-1/4-0-SP

Black, 1.75:1, Single Wall Tubing, Shrinks To .143 in...

\$3.583 per unit

Inventory: In-Stock

Add To Cart

TE Part #: NTFR-3/8-0-SP

Black, 1.75:1, Single Wall Tubing, Shrinks To .214 in...

\$4.294 per unit

Inventory: In-Stock

Add To Cart

TE Part #: TMS-SCE-3/32-2.0-9

Printable Tubing, Ladder, Military, 3:1 Shrink Ratio...

\$1.409 per unit

Inventory: In-Stock

Add To Cart