



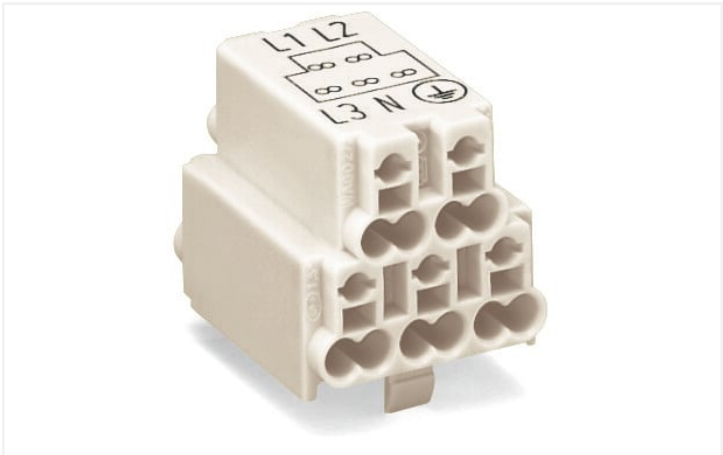

Color: white

Similar to illustration

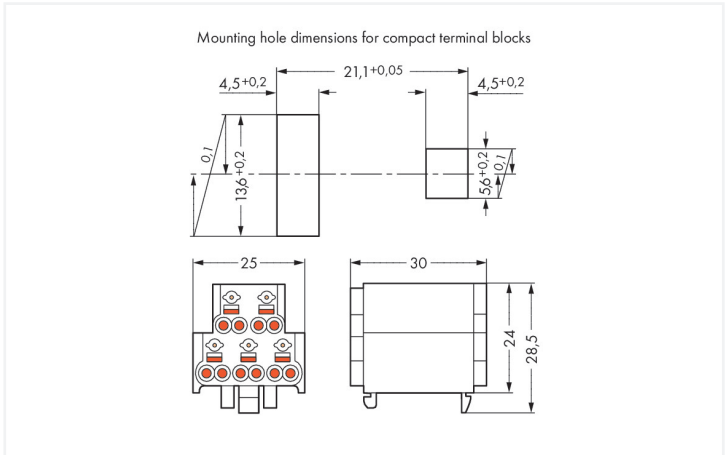

Dimensions in mm

Electrical data

Ratings per	IEC/EN 60664-1		
Overvoltage category	III	III	II
Pollution degree	3	2	2
Nominal voltage	-	400 V	-
Rated surge voltage	-	4 kV	-
Rated current	-	26 A	-

Connection data

Clamping units	20
Total number of potentials	5
Number of connection types	1

Connection 1	
Connection technology	PUSH WIRE®
Strip length	8 ... 9 mm / 0.31 ... 0.35 inches
Pole number	5

Physical data

Width	25 mm / 0.984 inches
Height	28.5 mm / 1.122 inches
Depth	30 mm / 1.18 inches

Material data

Note (material data)		Information on material specifications can be found here
Color	white	
Material group	I	
Insulation material (main housing)	Polyamide (PA66)	
Flammability class per UL94	V2	
Fire load	0.241 MJ	
Weight	14.9 g	



Commercial data	
Product Group	8 (Misc. Chassis Mount Blocks)
eCl@ss 10.0	27-14-11-04
eCl@ss 9.0	27-14-11-04
ETIM 8.0	EC000446
ETIM 7.0	EC000446
PU (SPU)	500 pcs
Packaging type	Bag
Country of origin	DE
GTIN	4044918407069
Customs tariff number	85369010000

Environmental Product Compliance	
RoHS Compliance Status	Compliant,No Exemption

Approvals / Certificates

General approvals



Approval	Standard	Certificate Name
CSA DEKRA Certification B.V.	C22.2 No. 158	70048844

Downloads

Environmental Product Compliance

Compliance Search	
Environmental Product Compliance 272-122/001-000	↓

Documentation

Additional Information			
Technical Section	03.04.2019	pdf 2027.26 KB	↓

CAD/CAE-Data

CAD data	
2D/3D Models 272-122/001-000	↓

CAE data	
EPLAN Data Portal 272-122/001-000	↓
WSCAD Universe 272-122/001-000	↓
ZUKEN Portal 272-122/001-000	↓



1 Compatible Products
1.1 Optional Accessories
1.1.1 Tool
1.1.1.1 Assembly tool



Item No.: 249-100
Operating tool; for terminal blocks with
snap-in ground contact