

527-128 M 01 L

Basic Part No. _____

Finish Symbol (Table II) _____

Dash No. (Table I, Note 2) _____

Entry Location: _____

L = Left Entry
R = Right Entry
T = Top Entry


TABLE II - FINISH OPTIONS

Symbol	Finish
B	Cadmium Plate, Olive Drab
J	Iridite, Gold Over Cadmium Plate over Nickel
M	Electroless Nickel
N	Cadmium Plate, Olive Drab, Over Nickel
NF	Cadmium Plate, Olive Drab, Over Electroless Nickel (500 Hour Salt Spray)
T	Cadmium Plate, Bright Dip Over Nickel (500 Hour Salt Spray)

TABLE I: CABLE ENTRY

Dash No.	A Max	Cable Range	
		Min	Max
01	.968 (24.6)	.156 (4.0)	.375 (9.5)
02 *	1.218 (30.9)	.375 (9.5)	.625 (15.9)

* See Note 2

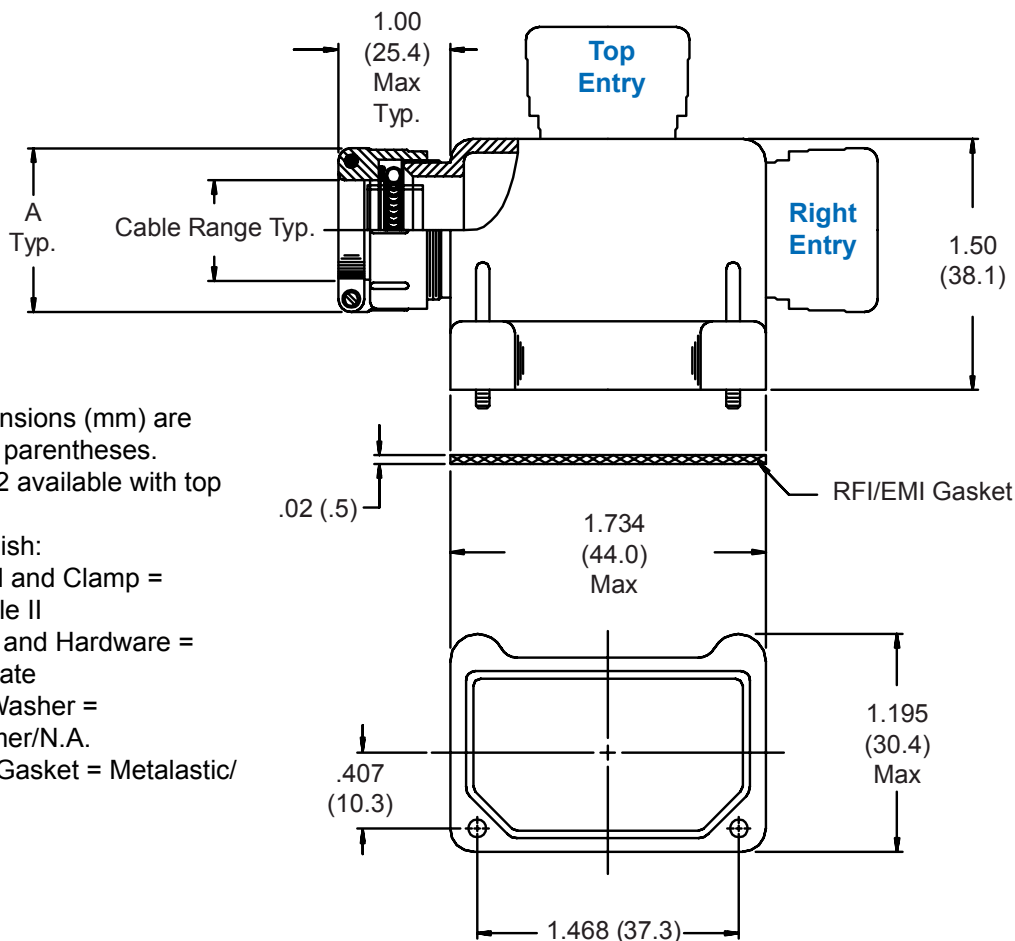

1. Metric dimensions (mm) are indicated in parentheses.
2. Dash No. 02 available with top entry only.
3. Material/Finish:
Backshell and Clamp =
Al Alloy/Table II
G-Spring and Hardware =
SST/Passivate
Friction Washer =
Fluoropolymer/N.A.
EMI/RFI Gasket = Metalastic/
N.A.