

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0795161101

Status:


Active

Overview:

Micro-Fit 3.0™ Connectors

Description:

Micro-Fit 3.0™ Overmolded Cable Assembly, 10 Circuit, 1.0m Length

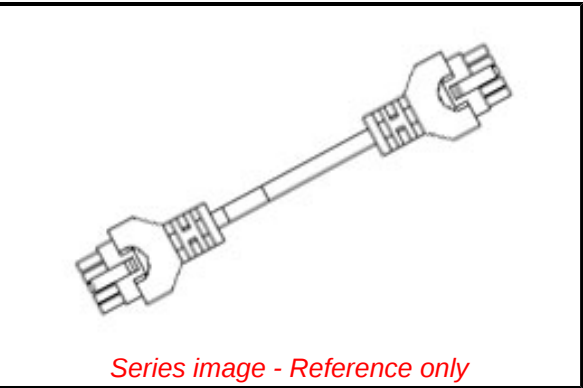

Series image - Reference only

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	Cable Assemblies
Series	79516
Assembly Configuration	Dual Ended Connectors
Comments	When using 30 AWG current max per contact is 5A.
Connector to Connector	Micro-Fit 3.0™ Both Ends
Overview	Micro-Fit 3.0™ Connectors
Product Name	Micro-Fit 3.0™
UPC	822348120550
Physical	
Cable Length	1.0m
Circuits (Loaded)	10
Color - Resin	Black
Gender	Female-Female
Lock to Mating Part	Yes
Material - Metal	Phosphor Bronze
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	Polyester, PVC
Net Weight	65.335/g
Packaging Type	Bag
Pitch - Mating Interface	3.00mm
Plating min - Mating	1.016µm
Plating min - Termination	1.016µm
Single Ended	No
Wire Insulation Diameter	N/A
Wire Size AWG	26
Wire/Cable Type	Jacketed
Electrical	
Current - Maximum per Contact	3.0A
Shielded	No
Voltage - Maximum	250V
Material Info	
Reference - Drawing Numbers	
Sales Drawing	SD-79516-004

EU ELV

Not Relevant

EU RoHS

Not Compliant

China RoHS

REACH SVHC

Not Contained Per -

ED/108/2014 (17 Dec

2014)

Halogen-Free

Status

Not Low-Halogen

Need more information on product

environmental compliance?

Email productcompliance@molex.com

Please visit the [Contact Us](#) section for any

non-product compliance questions.

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Reviewed

Search Parts in this Series

79516 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION