



© 2020 TE Connectivity Ltd. family of companies. All Rights Reserved

**X4-1.0-0-SP-SM**

✓ ACTIVE

Raychem SWFR X4, Heat Shrink Tubing, Black, Single Wall Type, 1.15 Expanded Inside Diameter (Min) .045 Expanded Inside Diameter (Min)

Raychem | Raychem SWFR X4

TE Internal #: **EM7500-000**TE Internal Description: **X4-1.0-0-SP-SM**Primary Product Color : **Black**Wall Type : **Single**[+ More](#)[Add to List](#) ▾[Get Free Samples](#)[Similar Products](#)[Digital Datasheet](#)**Compatible Parts & Tooling**

## DOCUMENTS

### PRODUCT DRAWINGS

**X4-1.0-0-SP-SM**

 [X4-1.0-0-SP-SM](#)

English

Dimensional Drawing

X4-1.0-0-SP-SM

 [X4-1.0-0-SP-SM](#)

English

DATASHEETS & CATALOG PAGES

Very-Thin-Wall, Highly Flame-Retardant, Zero Halogen, Metric-Sized Heat-Shrinkable Tubing

 [ENG\\_DS\\_SWFR\\_X4\\_3.pdf](#)

English

- FEATURES

+
- PRODUCT COMPLIANCE

+

# Compatible Parts

## Filter By Specification



TOOLING

CJ2087-000

Portable Crimp Tools, Heating Tool

In-Stock

VIEW PRODUCT



TOOLING

CV1981-ST-230V1600W-EU

CV1981-ST-230V1600W-EU


In-Stock

VIEW PRODUCT

# Products with Similar Specs

## THIS PRODUCT

HEAT SHRINK TUBING  
**X4-1.0-0-SP-SM**  
Raychem SWFR X4, Heat Shrink Tubing,  
Black, Single Wall Type...

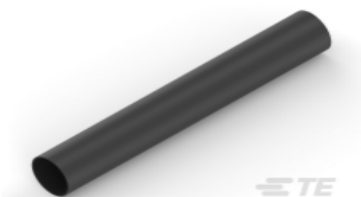


From **\$0.850** **In-Stock** 

Primary Product Color : **Black**  
Wall Type : **Single**  
Expanded Inside Diameter (Min) : **1.15 mm**  
Recovered Inside Diameter (Max) : **.5 mm**  
Shrink Ratio : **2:1**

## TOP RESULTS ?


HEAT SHRINK TUBING  
**X4-0.8-0-SP-SM**  
Raychem SWFR X4, Heat Shrink Tubing,  
Black, Single Wall Type, .95...

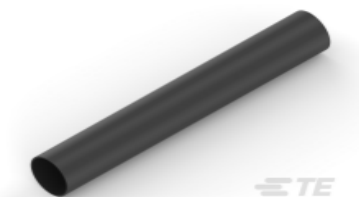

From **\$0.807** **In-Stock** 

Primary Product Color : **Black**  
Wall Type : **Single**  
Expanded Inside Diameter (Min) : **.95 mm**  
Recovered Inside Diameter (Max) : **.4 mm**  
Shrink Ratio : **2:1**

HEAT SHRINK TUBING  
**X4-0.6-0-SP**  
Raychem SWFR X4, Heat  
Black, Single Wall Type, .

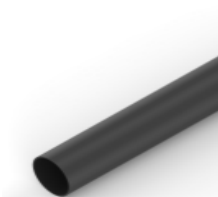

From **\$1.094**

Primary Product Color : **Black**  
Wall Type : **Single**  
Expanded Inside Diameter (Min) : **.6 mm**  
Recovered Inside Diameter (Max) : **.3 mm**  
Shrink Ratio : **2:1**

[View All Similar Products](#)


# Customers Also Bought



TE Model / Part #  
**T4162114004-005**  
M8/M12 Cable Assemblies,  
Sensor/Actuator, 4...

\$39.951 per unit  
Inventory: 42

 **Add To Cart**

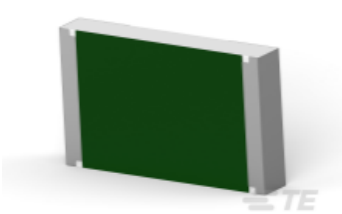

TE Model / Part #  
**35405K6JT**  
CGS 3540, Surface Mount  
Resistors, Power Resistor, 2...

\$1.040 per unit  
Inventory: 3986

 **Add To Cart**




TE Model / Part # **X4-0.8-0-SP-SM**  
Raychem SWFR X4, Heat  
Shrink Tubing, Black, Single...

\$0.807 per unit  
Inventory: 14

 **Add To Cart**

Also in the Series | [Raychem SWFR X4](#)

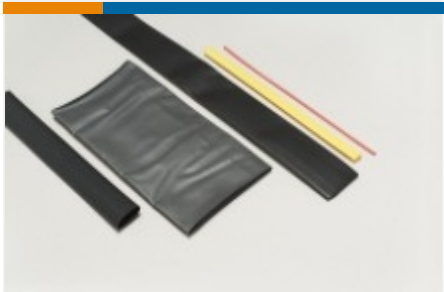

Heat Shrink Tubing  
(16)