


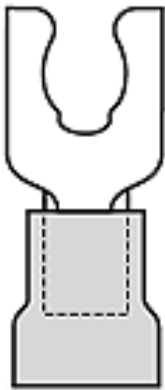

Part Number : [190990035](#)
Product Description : InsulKrimp Snap Spade for 16-14 AWG Wire, Stud Size 10 (M5), Mylar Tape Carrier, Length 23.34mm, Blue
Series Number : 19099
Status : Active
Product Category : Ring and Spade Terminals
Engineering Number : BB-2717-10XT



Documents & Resources

Drawings
[190990035_sd.pdf](#)

Specifications
[PS-19902-009-001.pdf](#)
[PS-19902-011-001.pdf](#)
[PS-19902-015-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Not Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2024)6225-DC (07 Nov 2024)
EU RoHS	Compliant per EU 2015/863

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	Active
Category	Ring and Spade Terminals
Series	19099
Description	InsulKrimp Snap Spade for 16-14 AWG Wire, Stud Size 10 (M5), Mylar Tape Carrier, Length 23.34mm, Blue
Keyword	Spade Terminal, Spade Terminals
Product Name	InsulKrimp
Type	Spade Snap
UPC	800753089242

Agency

CSA	LR18689
UL	E32244

Physical

Barrel Type	Closed
Color - Resin	Blue
Flammability	94V-0
Insulation	PVC
Material - Plating Mating	Tin
Net Weight	0.859/g
Packaging Type	Adhesive Tape on Reel
Stud Size	10 (M5)
Wire Insulation Diameter	4.40mm max.
Wire Size (AWG)	14, 16

Application Tooling

Global

Description	Part Number
ATP Crimp Dies for the Tape Crimp Module and ATP-101 & 301 Press	<u>192880123</u>
Mini-Mac Applicator	<u>638850400</u>

This document was generated on Mar 09, 2025