

THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.

Material	High Conductivity Seamless Copper Tube
Plating	Electro-Tin
Wire Size	500 kcmil
Wire Type	Stranded Copper; Class B: Compact, Compressed or Concentric, Class C: Concentric
Wire Strip Length	1-13/16 in.
Stud Size	3/8 in.
UL Listed Wire Connector	Yes, for applications up to 35kv. Consult cable manufacturer for voltage stress relief instructions with applications greater than 2000 volts.
UL Temperature Rating	90 ° C
C.S.A Certified Wire Connector	Yes
Panduit Color Code on Barrel	BROWN
Panduit Die Index No. on Barrel	P87
Alternate Industry Die Index No. () on Barrel	(20)




CERTIFIED



LISTED

Wire Connector

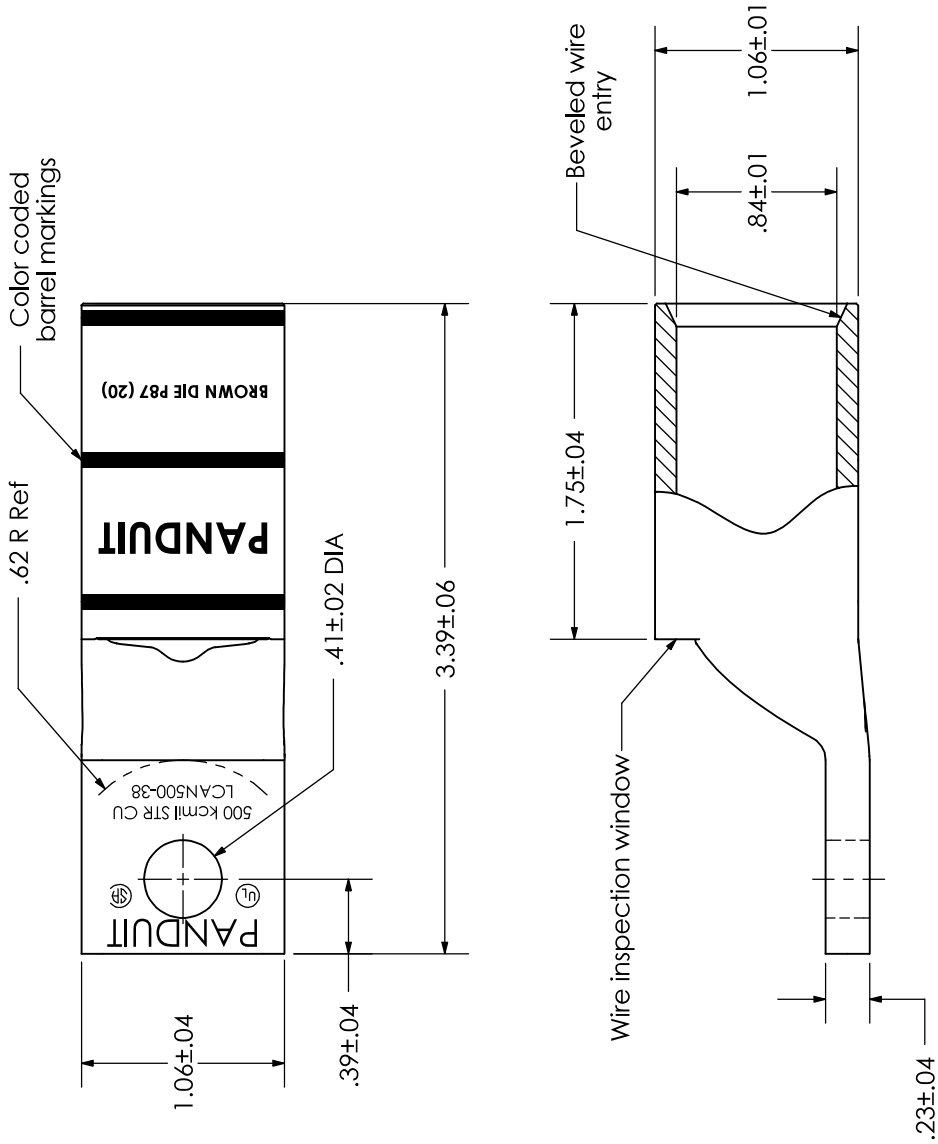

				PANDUIT CORP. TINLEY PARK, ILLINOIS			
				LCAN500-38-6			
				Copper Lug - One-Hole, Narrow Tongue, Standard Barrel			
				TONGUE THICKNESS WAS .22±.01			
01	11/08	DRL	DRL	DESCRIPTION		ECN	SCALE N/A
REV	DATE	BY	CHK			DRAWING NO / CAD FILE	LCAN500-38-CUST