


Specification Sheet

Part Number: 151-00667

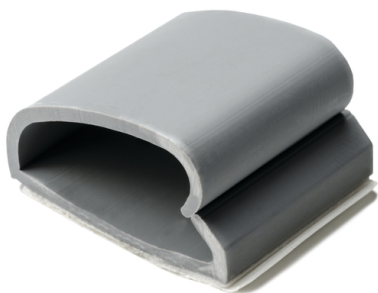

Lead-in angle design allows for quick and easy installation of wires and cables.

Rubber based adhesive allows for a permanent bond to most surfaces.

WAC Adhesive Cable Clamp, 0.75" Max. Bundle Dia, PVC, Gray, 500/pkg

Article Number 151-00667

Type WAC075

Color Gray (GY)

Quantity Per pack

Product Description The WAC Adhesive cable clamps are designed with lead in angles allowing for easy insertion of wires and cables. The rubber based adhesive allows for a permanent bond to most surfaces. Available in two sizes.

Short Description WAC Adhesive Cable Clamp, 0.75" Max. Bundle Dia, PVC, Gray, 500/pkg

Global Part Name WAC075-PVC-GY

Length L (Imperial)	1.13
Length L (Metric)	28.7
Width W (Imperial)	1.0
Width W (Metric)	25.4
Bundle Diameter Min (Imperial)	0.5
Bundle Diameter Min (Metric)	12.7
Bundle Diameter Max (Imperial)	0.75
Bundle Diameter Max (Metric)	19.1
Height H (Imperial)	0.62
Height H (Metric)	15.8
Material	Polyvinylchloride (PVC)
Material Shortcut	PVC
Adhesive	Self adhesive
Flammability	UL 94 V-0 (excluding adhesive)
UV Resistant (Yes/No)	No

Use Conditions For Indoor Use Only

Operating Temperature +122°F (+50°C)

Reach Compliant (Article 33) No

Package Quantity (Imperial) 500

Package Quantity (Metric) 500

Customs Number 3926909988

7930 N. Faulkner Road, Milwaukee, WI 53224

Phone: (800) 537-1512 | Email: corp@htamericas.com

© 2026 HellermannTyton. All Rights Reserved.

[Contact Us](#) [RoHS/WEEE Compliance](#) [Privacy Policy](#) [Cookie Policy](#) [Terms and Conditions](#)