



Product Search Assistant (β version)

We suggest candidate products with similar specifications

in the same size or small size

Small size



High capacity



High withstand voltage



High temperature response



Focus on DC bias characteristics



Reference information


Packaging code	specification	Minimum order unit
L	Dia. 180 mm embossed tape	3000
K	ϕ 330mm embossed tape	10000

Mass (typical value)	
1 piece	17.0 mg
ϕ 180 mm reel	102g



Characteristic data graph

Frequency characteristics | Z |

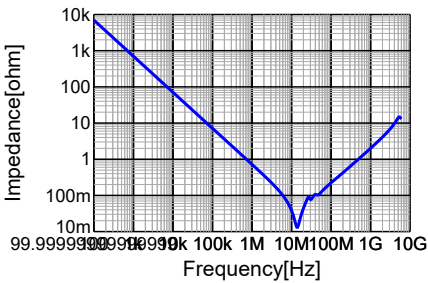


GCM21BR11H224KA01, DC 0 V, 20 deg C



詳細設定

Frequency characteristic R

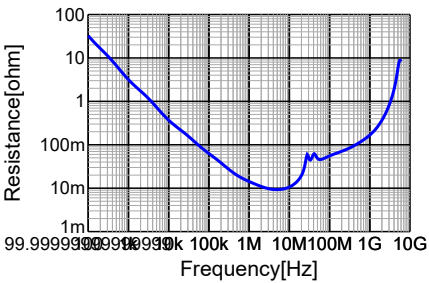


GCM21BR11H224KA01, DC 0 V, 20 deg C



詳細設定

DC bias characteristics

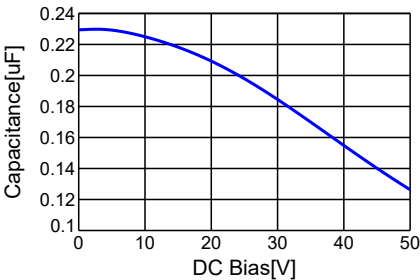


GCM21BR11H224KA01, capacitance, 20.0degC, AC1.0Vrms



詳細設定



AC voltage characteristics

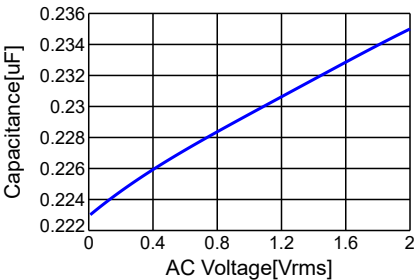

GCM21BR11H224KA01, capacitance, DC0V, 20.0degC



詳細設定

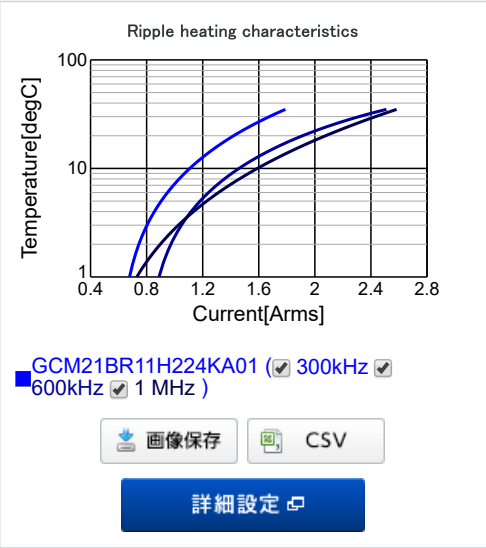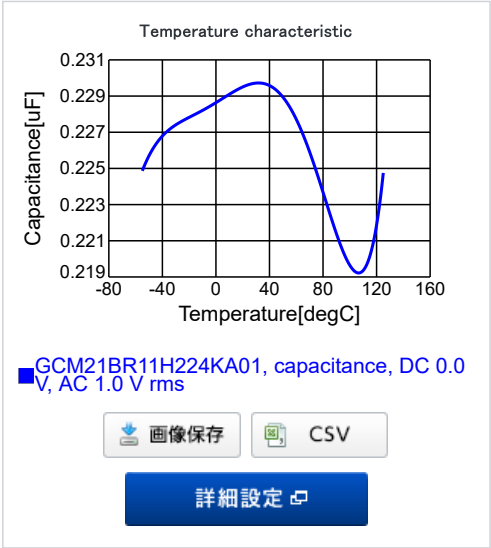

 更に詳しいグラフを見る

[Return to the top of this page](#)