


MMZ1005F560CT000

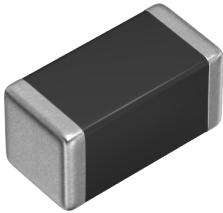

Applications	 Commercial Grade
Feature	High Speed High speed signal line
Series	MMZ
Status	 Production
Brand	TDK





Size	
Length(L)	1.00mm ±0.05mm
Width(W)	0.50mm ±0.05mm
Thickness(T)	0.50mm ±0.05mm
Recommended Land Pattern (A)	0.50mm Nom.
Recommended Land Pattern (B)	0.40mm Nom.
Recommended Land Pattern (C)	0.50mm Nom.

Electrical Characteristics	
Impedance at 100MHz	56Ω ±25%
Rated Current	100mA
DC Resistance (Max.)	700mΩ

Other	
Operating Temp. Range (Including Self-Temp. Rise)	-55 to 125°C
Soldering Method	Reflow Iron Soldering
AEC-Q200	NO
Packing	Punched (Paper)Taping [180mm Reel, Tape width 8mm]
Package Quantity	10000pcs
Weight	0.001g



Characteristic Graphs(This is reference data, and does not guarantee the products characteristics.)

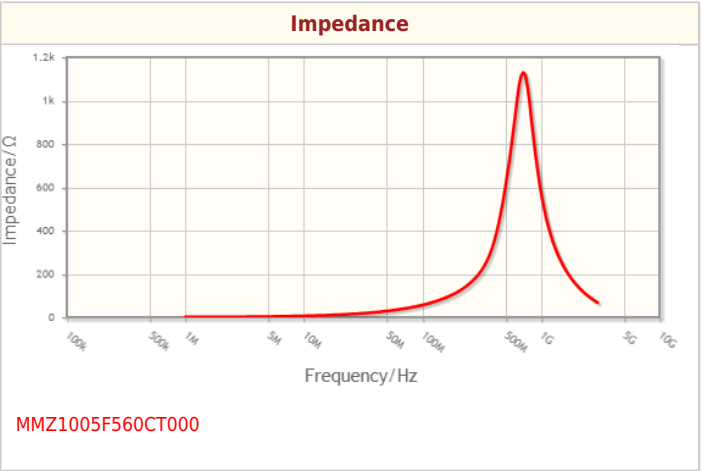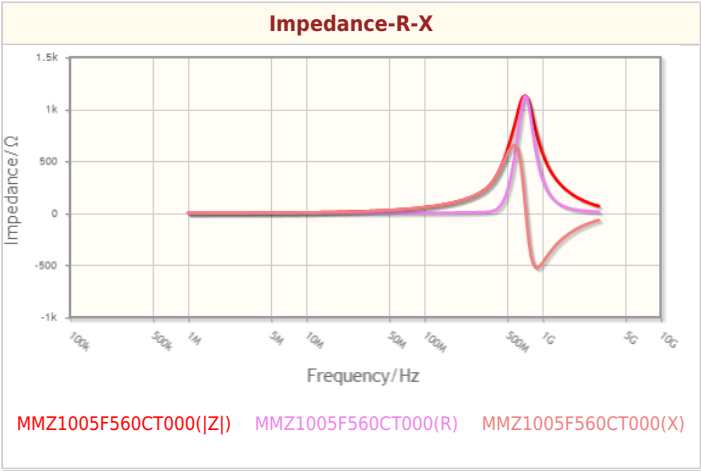

MMZ1005F560CT000



Associated Images

