




Tripp Lite
1111 W. 35th Street
Chicago, IL 60609 USA
Telephone: 773.869.1234
www.tripplite.com

Cat5e 350 MHz Solid Core Outdoor-Rated (UTP) PVC Bulk Ethernet Cable - Gray, 1000 ft. (304.8 m)

MODEL NUMBER: N028-01K-GY

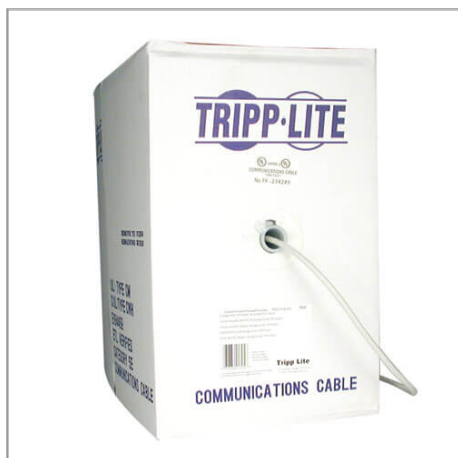

Highlights

- UV Rated jacket prevents drying and cracking
- 4PR Solid conductors for Low Attenuation Loss
- CMX Outdoor rating; Temp range -40F to +140F

Package Includes

1000ft. Box Cat5e Outdoor Rated
PVC Bulk Cable

Features

- UV Rated jacket prevents drying and cracking
- 4PR Solid conductors for Low Attenuation Loss
- CMX Outdoor rating; Temp range: -40F to +140F
- 1000-ft. Pull-box, length marked every two feet
- Terminate with Tripp Lite N030-010 Solid wire Cat5e RJ45 plugs

Specifications

OVERVIEW	
UPC Code	037332141491
Technology	Cat5/5e
POWER	
Power Over Cable (PoC) Support	No
PHYSICAL	
Cable Jacket Color	Gray
Cable Jacket Material	PVC
Cable Jacket Rating	CMR; CMX
Cable Shielding	UTP



Tripp Lite
1111 W. 35th Street
Chicago, IL 60609 USA
Telephone: 773.869.1234
www.tripplite.com

Cable Outer Diameter (OD)	5.5MM
Number of Conductors	4 Pair
Conductor Material	Solid Copper
Conductor Gauge	24 AWG
Cable Length (ft.)	1000
Cable Length (m)	304.88
Cable Length (in.)	12000
Cable Length (cm)	30480
Shipping Dimensions (hwd / cm)	22.86 x 37.08 x 38.10
Shipping Dimensions (hwd / in.)	9.00 x 14.60 x 15.00
Shipping Weight (kg)	11.29
Shipping Weight (lbs.)	24.90
ENVIRONMENTAL	
Operating Temperature Range	14 to 104 F (-10 to 40 C)
Storage Temperature Range	5 to 122 F (-15 to 50 C)
Operating Humidity Range	0% to 90% RH, Non-Condensing
Storage Humidity Range	0% to 90% RH, Non-Condensing
COMMUNICATIONS	
Bandwidth per TIA Standard	100 MHz
Maximum Bandwidth as Tested	350 MHz
Network Compatibility	1 Gbps (Gigabit)
IEEE Standards Supported	802.3ab
CONNECTIONS	
Side A - Connector 1	BARE WIRE
Side B - Connector 1	BARE WIRE
Crossover Wiring	No
Contact Plating	Gold
Connector Type	Molded
Wiring Configuration	EIA/TIA 568B
FEATURES & SPECIFICATIONS	
IP68 Rated	No
Snagless Connector	No
Antibacterial	No



Tripp Lite
1111 W. 35th Street
Chicago, IL 60609 USA
Telephone: 773.869.1234
www.tripplite.com

STANDARDS & COMPLIANCE	
Certifications	RoHS, REACH
WARRANTY	
Product Warranty Period (Worldwide)	Lifetime limited warranty

© 2022 Tripp Lite. All rights reserved. All product and company names are trademarks or registered trademarks of their respective holders. Use of them does not imply any affiliation with or endorsement by them. Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice. Tripp Lite uses primary and third-party agencies to test its products for compliance with standards. See a list of Tripp Lite's testing agencies: <https://www.tripplite.com/products/product-certification-agencies>