


ITEM NO.	PART NUMBER	DESCRIPTION	QTY.	COMPONENT NOTES
1	30-00941	Wire, 9C BC, 20 AWG, UL20280, 300V, 80C, 7.8 mm, braided shield, FT2, TPU	1	

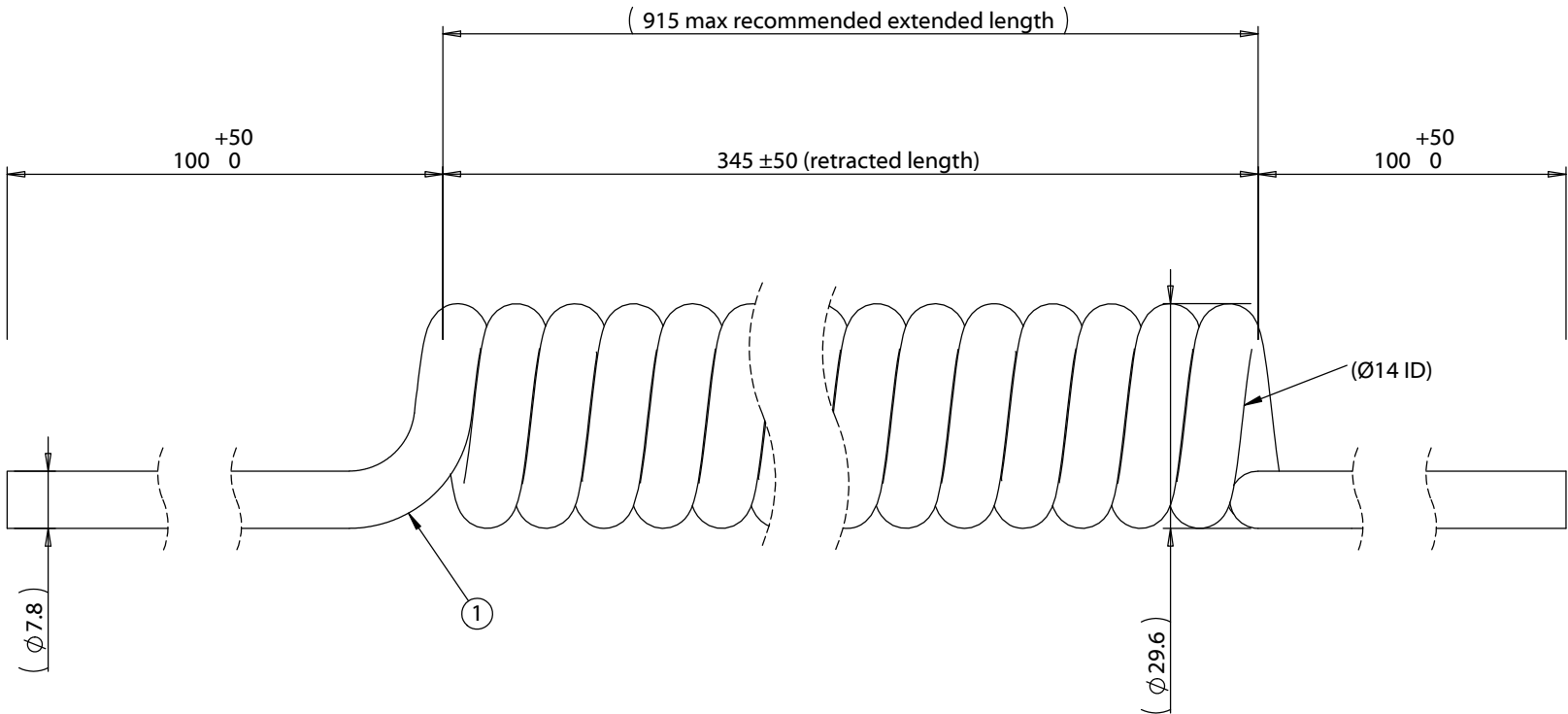

Notes:
Total wire length for resistance calculation: 3250 mm

Revision:	Date:	Description:	Prepared:	Notes: RoHS and REACH compliant Phthalate and halogen free Function test: no open, no short circuit, no intermittent	TENSILITY tel 1.541.323.3228 800 877.670.7118 fax 1.541.323.4202 web tensility.com		
A	10/18/2018	Initial release	Verified:				
			Dimensions are in millimeters. Tolerances: X: ± 0.5 mm X.X: ± 0.3 mm X.XX: ± 0.05 mm	Description: Coiled cable, 1115 mm, 9C blunt cut to same, 20 AWG, 7.8 mm, TPU, shielded, 30-00941 wire	Size:	Part number:	
					A	31-00129	
					Scale: 1:1		Sheet 1 of 1

To see a custom version of this cable assembly, call Tensility at 541-323-3228 or email engineering@tensility.com