


Part number description :

10134372-XXXLF

LF: Lead Free, RoHs compliant, see note

XXX : Color ref or/and version

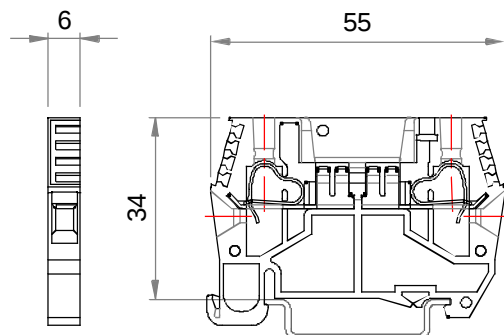

Note : THIS PRODUCT MEETS EUROPEAN UNION DIRECTIVES
AND OTHER COUNTRY REGULATIONS AS PER GS-47-0004

ACCESSORIES

Item	Description
Marking	
10134398-001LF	Blank single-digit marking tags
10134398-002LF + 10134398-011LF	Printed single-digit marking tags numbered : 1÷0
10134398-012LF + 10134398-041LF	Printed single-digit marking tags with letter: A÷Z
10134399-001LF	Marking tag adapter
10134400-001LF	Blank Marking tags
10134401-001LF	Blank Marking tags

DIN RAIL system - Mounting and Installation material

10134392-001LF	Steel Omega Rail TH35x7,5mm -2mt length
10134393-001LF	Slotted Steel Omega Rail TH35x7,5mm -2mt length
10134394-001LF	Steel Omega Rail TH35x15mm -2mt length
10134395-001LF	Slotted Steel Omega Rail TH35x15mm -2mt length
10134387-001LF	Angled support bracket
10134389-001LF	End Bracket for TH35 Omega rail -Width 9mm
10134390-001LF	End Bracket for TH35 Omega rail -Width 6mm
10134391-001LF	Fast-snap End Bracket for TH35 Omega rail

Additional items

10134378-001LF	End Plate for Terminal Blocks: F2.5 - F4
10134378-002LF	Separator for Terminal Blocks: F2.5 - F4
10134420-001LF	External Jumper bar 12 poles,pitch 9,1mm JB - blue
10134271-003LF	Ratchet Cutting Tool for external jumper bar JB -blue
10134379-001LF	Disconnecting Plug for Terminal Blocks: F2.5 - F4
10134382-001LF	Automotive fuse – All types
10134383-001LF	Automatic reset thermal Circuit Breaker – All types
10134384-001LF	Thermal circuit breaker – All types
10134385-001LF	Thermal Circuit Breaker with manual release – All types
10134386-001LF	Thermal Circuit Breaker with push-push actuation – All types
10134380-001LF	Holder for GlassFuse 5x20mm for Terminal Blocks: F2.5- F4
10134381-001LF	Holder for GlassFuse 6,3x32mm for Terminal Blocks: F2.5- F4

PN	Colour	Version
10134372-001LF	grey	(A)
10134372-002LF	grey	(B) LED 12V
10134372-003LF	grey	(C) LED 24V

TECHNICAL DATA / DIMENSIONS


Dimensions	
Width mm	6.0
Length mm	55.0
Height mm	34.0
Mounting type (EN 60715)	Omega TH35
Technical data	
Maximum load current	25A
Insulating material	PA
Self-extinguishing degree acc. to UL94	V0
Rated surge voltage	2.5
Pollution degree	3
Surge voltage category	III
Insulating material group	I
Nominal Voltage	300V
Nominal Current	25A (STR)
Connection data	
Conductor cross-section solid min/max	0.50 / 4 mm ²
Conductor cross-section stranded min/max	0.50 / 4 mm ²
AWG min/max	24-10AWG
Max conductor cross-section stranded with ferrule with plastic sleeve	4 mm ² / L=12 mm
Stripping length	max 9 mm

APPROVALS

EN60947-7-3 2.5mm² – 250V – 25A

AWG 24-10(STR) – 300V – 5A

AWG 24-12(SOL) – 300V – 0A

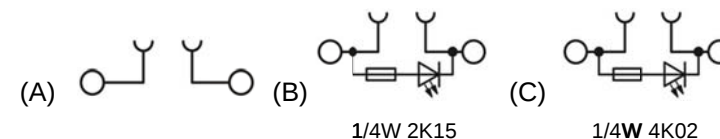

spec ref	dr	Aymeric Soudy	23-07-2015	projection	size	A3	scale	1:1
tolerance std	eng	Aymeric Soudy	23-07-2015	MM	ecn no			
ISO 406	chr			product family	DIN Terminal Block	rel level		
ISO 1101	appr	Aymeric Soudy	23-07-2015	Flat-type fuse holder Screwless	10134372	rev	A	
surface	linear	0.X	± 0.3	Terminal block F4				
		0.XX	± 0.1					
		0.XXX	± 0.05					
ISO 1302	angular	0°	± 2°					