


Cable duct - CD-HF 60X100 BU - 3240597

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)

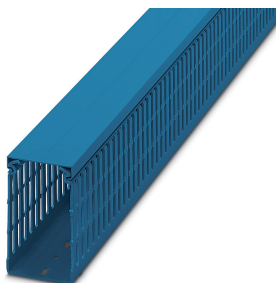

Cable duct for installation and mounting in control cabinets, blue, halogen-free, comprising upper part and mounting base, width: 60 mm, height: 100 mm, length: 2000 mm



Key Commercial Data

Packing unit	1 pc
Minimum order quantity	8 pc
GTIN	 4 046356 624398
GTIN	4046356624398
Custom tariff number	39259020
Country of origin	Germany

Technical data

Dimensions

Length (b)	2000 mm
Width (a)	60 mm
Height (c)	100 mm

Ambient conditions

Ambient temperature (operation)	-40 °C ... 90 °C
---------------------------------	------------------

General

Color	blue
Components	halogen-free
Material	PC/ABS
Flammability rating according to UL 94	V0

Cable duct - CD-HF 60X100 BU - 3240597

Technical data

General

Nominal cross section	4239 mm ²
-----------------------	----------------------

Standards and Regulations


Halogen-free	yes
Connection in acc. with standard	CSA

Environmental Product Compliance

China RoHS	Environmentally friendly use period: unlimited = EFUP-e
	No hazardous substances above threshold values

Drawings

Dimensional drawing

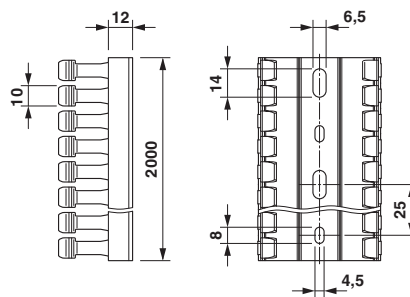

Base perforation according to DIN EN 50085

Classifications

eCl@ss

eCl@ss 10.0.1	27400703
eCl@ss 11.0	27400703
eCl@ss 4.0	27140600
eCl@ss 4.1	27140600
eCl@ss 5.0	27140600
eCl@ss 5.1	27140600
eCl@ss 6.0	27400700
eCl@ss 7.0	27400703
eCl@ss 9.0	27400703

ETIM

ETIM 4.0	EC000012
ETIM 6.0	EC000012

Cable duct - CD-HF 60X100 BU - 3240597

Classifications

ETIM

ETIM 7.0	EC000012
----------	----------

UNSPSC

UNSPSC 6.01	30101815
UNSPSC 7.0901	30101815
UNSPSC 11	30101815
UNSPSC 12.01	30101815
UNSPSC 13.2	39131712
UNSPSC 18.0	39131712
UNSPSC 19.0	39131712
UNSPSC 20.0	39131712
UNSPSC 21.0	39131712

Approvals

Approvals

Approvals

CSA / VDE Zeichengenehmigung / EAC

Ex Approvals

Approval details

CSA		http://www.csagroup.org/services-industries/product-listing/	248269
-----	---	---	--------

VDE Zeichengenehmigung		http://www2.vde.com/de/Institut/Online-Service/VDE-gepruefteProdukte/Seiten/Online-Suche.aspx	40028972
------------------------	---	---	----------

EAC			RU C- DE.PB68.W.00513
-----	---	--	--------------------------

Cable duct - CD-HF 60X100 BU - 3240597

Accessories

Accessories

Filler plug

Fastening clip - RVT-PA 4 - 3240498



Plastic body-bound rivet, for hole diameter of 4 mm and a material thickness of 1.5 ... 6 mm

Fastening clip - RVT-PA 6 - 3240499



Plastic body-bound rivet, for hole diameter of 6 mm and a material thickness of 1.5 ... 6 mm

Riveting tools

Tool - UNIFOX-RVT P 4 - 1212478



Rivet setting tool, for use with RVT-PA 4 plastic body-bound rivets

Tool - UNIFOX-RVT P 6 - 1212509



Rivet setting tool, for use with RVT-PA 6 plastic body-bound rivets
