


# CD 40X60 WH - Cable duct

3240625

<https://www.phoenixcontact.com/us/products/3240625>



Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

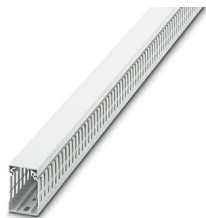

Cable duct for installation and mounting in control cabinets, white, comprising upper part and mounting base, width: 40 mm, height: 60 mm, length: 2000 mm

## Your advantages

- Predetermined breaking point enables tool-free, burr-free removal of bars
- Thanks to its leverage and special cutting geometry, the PPS CD cable duct cutter enables easy, burr-free cutting with minimum effort
- Easy, burr-free cutting with minimum effort using the CUTFOX-CD cable duct cutter
- The wide, diagonal heads of the cable duct bars make it easy to fit the cover and hold it securely in place
- Installed conductors are securely held in place by means of wire retaining clips that can be snapped onto bars on the side
- Plastic body-bound rivets enable easy fixing of cable ducts using the rivet setting tool

## Commercial data

Item number	3240625
Packing unit	1 pc
Minimum order quantity	20 pc
Sales key	BE74
Product key	BE7433
Catalog page	Page 581 (C-3-2019)
GTIN	4046356629416
Weight per piece (including packing)	870 g
Weight per piece (excluding packing)	870 g
Customs tariff number	39259020
Country of origin	DE

# CD 40X60 WH - Cable duct

3240625

<https://www.phoenixcontact.com/us/products/3240625>



## Technical data


### Product properties

Product type	Wiring duct
--------------	-------------

### Connection data

Nominal cross section	1404 mm <sup>2</sup>
-----------------------	----------------------

### Dimensions

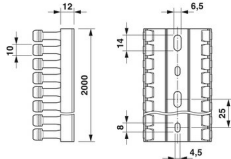Dimensional drawing	
Width	40 mm
Height	2000 mm
Depth	60 mm
Length	2000 mm

### Material specifications

Color	white
Material	PVC
Flammability rating according to UL 94	V0
Components	Lead-free

### Cable/line

Halogen-free	no
--------------	----

### Environmental and real-life conditions

Ambient conditions	
Ambient temperature (operation)	-5 °C ... 60 °C

# CD 40X60 WH - Cable duct


3240625

<https://www.phoenixcontact.com/us/products/3240625>



## Drawings

Dimensional drawing

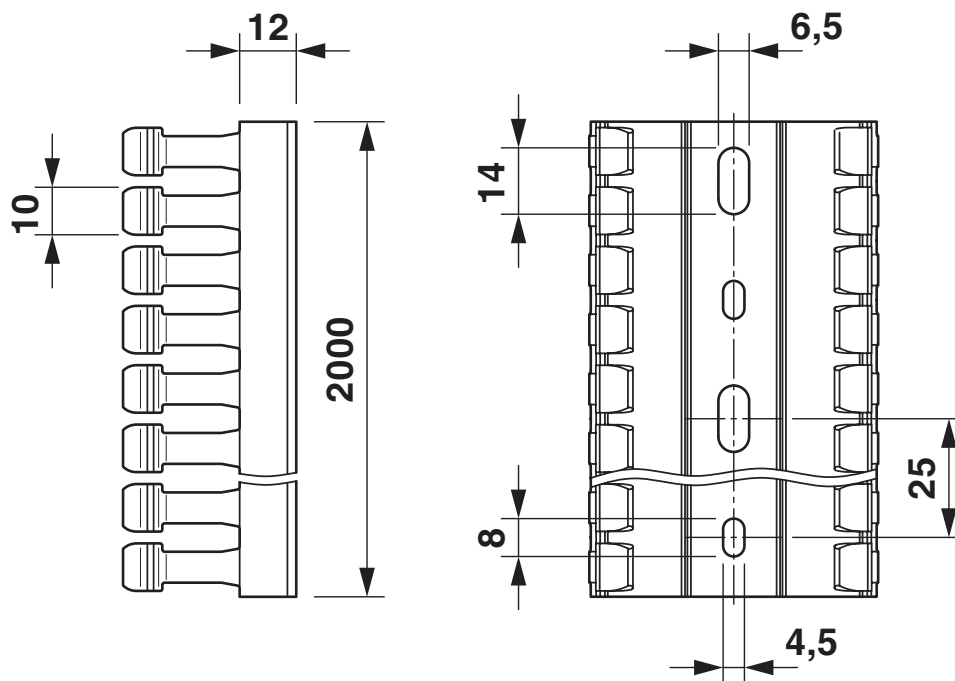

Base perforation according to DIN EN 50085

# CD 40X60 WH - Cable duct

3240625

<https://www.phoenixcontact.com/us/products/3240625>



## Approvals

To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/3240625>



**CSA**

Approval ID: 248269



**UL Recognized**

Approval ID: FILE E 328576



**VDE Zeichengenehmigung**

Approval ID: 40027969



**EAC**

Approval ID: RU C-DE.PB68.W.00478

# CD 40X60 WH - Cable duct

3240625

<https://www.phoenixcontact.com/us/products/3240625>



## Classifications

### ECLASS

ECLASS-11.0	27400703
ECLASS-12.0	27400703
ECLASS-13.0	27400703

### ETIM

ETIM 9.0	EC000012
----------	----------

### UNSPSC

UNSPSC 21.0	39131700
-------------	----------

# CD 40X60 WH - Cable duct

3240625

<https://www.phoenixcontact.com/us/products/3240625>



## Environmental product compliance

China RoHS	Environmentally friendly use period: unlimited = EFUP-e
	No hazardous substances above threshold values

# CD 40X60 WH - Cable duct

3240625

<https://www.phoenixcontact.com/us/products/3240625>



## Accessories

### RVT-PA 4 - Fastening clip

3240498

<https://www.phoenixcontact.com/us/products/3240498>



Plastic body-bound rivet, for hole diameter of 4 mm and a material thickness of 1.5 ... 6 mm

---

### RVT-PA 6 - Fastening clip

3240499

<https://www.phoenixcontact.com/us/products/3240499>



Plastic body-bound rivet, for hole diameter of 6 mm and a material thickness of 1.5 ... 6 mm

## CD 40X60 WH - Cable duct

3240625

<https://www.phoenixcontact.com/us/products/3240625>



## UNIFOX-RVT P 4 - Tool

1212478

<https://www.phoenixcontact.com/us/products/1212478>

Rivet setting tool, for use with RVT-PA 4 plastic body-bound rivets



---

## UNIFOX-RVT P 6 - Tool

1212509

<https://www.phoenixcontact.com/us/products/1212509>

Rivet setting tool, for use with RVT-PA 6 plastic body-bound rivets



---

Phoenix Contact 2023 © - all rights reserved  
<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)