

5650934-5 ✓ ACTIVE

EUROCARD | Eurocard Type R

TE Internal #: 5650934-5

Plug, Wire-to-Board, 64 Position, 2.54 mm [.1 in] Centerline, Printed Circuit Board, 3 Row, Vertical, 32 Column, Eurocard Type R, Eurocard Connectors

[View on TE.com >](#)



Connectors > PCB Connectors > Backplane Connectors > Eurocard Connectors



Connector & Housing Type: **Plug**

Connector System: **Wire-to-Board**

Termination Post & Tail Length: **4.57 mm [.18 in]**

Number of Positions: **64**

Centerline (Pitch): **2.54 mm [.1 in]**

Features

Product Type Features

Connector & Housing Type	Plug
Connector System	Wire-to-Board
Connector & Contact Terminates To	Printed Circuit Board
Performance Level	II

Configuration Features

Mating & Unmating Configuration	Make First / Break Last
Number of Positions	64
Number of Rows	3
PCB Mount Orientation	Vertical
Number of Columns	32
Rows Loaded	A, C
Number of Signal Positions	64

Body Features

Primary Product Color	Gray
-----------------------	------



Contact Features

Contact Base Material	Brass
Contact Type	Pin
Contact Current Rating (Max)	1.5 A

Termination Features

Termination Method to PCB	Through Hole - Solder
Termination Post & Tail Length	4.57 mm[.18 in]

Mechanical Attachment

Connector Mounting Type	Board Mount
Mating Alignment	Without
PCB Mount Retention	Without

Housing Features

Housing Material	Glass-Filled Polymer
Centerline (Pitch)	2.54 mm[.1 in]

Dimensions

PCB Thickness (Recommended)	1.57 mm[.062 in]
Connector Height	11.51 mm[.453 in]
Row-to-Row Spacing	2.54 mm[.1 in]

Usage Conditions

Operating Temperature Range	-55 – 105 °C[-67 – 221 °F]
-----------------------------	----------------------------

Operation/Application

Circuit Application	Signal
---------------------	--------

Packaging Features

Packaging Method	Box
------------------	-----

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	有害物质含量符合标准要求 No Restricted Substance(s) Above Threshold
EU REACH Regulation (EC) No. 1907/2006	



Current ECHA Candidate List: JUNE 2025 (250)
 Candidate List Declared Against: JUNE 2025 (250)
 Does not contain REACH SVHC

Halogen Content Not Low Halogen - contains Br or Cl > 900 ppm.

Solder Process Capability Wave solder capable to 265°C

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



TE Part # 5650897-5
 ASSY,RECEPT,EURO,TYPE R,L-FREE, A&C,64/96



TE Part # 5650945-5
 ASSY,PIN,EUROCARD,TYPE C,LEAD-



TE Part # 5148296-2
 ASSY,RECEPT,EUROCARD,TYPE R,L-FREE,A&B,6



TE Part # 166811-2
 RV100 FEM CON 2X32P



TE Part # 5650897-4
 ASSY,RECEPT,EURO,TYPE R,L-FREE, A&C,64/96



TE Part # 5650870-5
 ASSEMBLY,RECEPTACLE,EURO,TYPE





TE Part # 5650933-5
 ASSY,PIN,EUROCARD,TYPE R,LEAD-



TE Part # 650945-5
 064 EURO TYPE C PIN ST ASSY



Also in the Series | Eurocard Type R

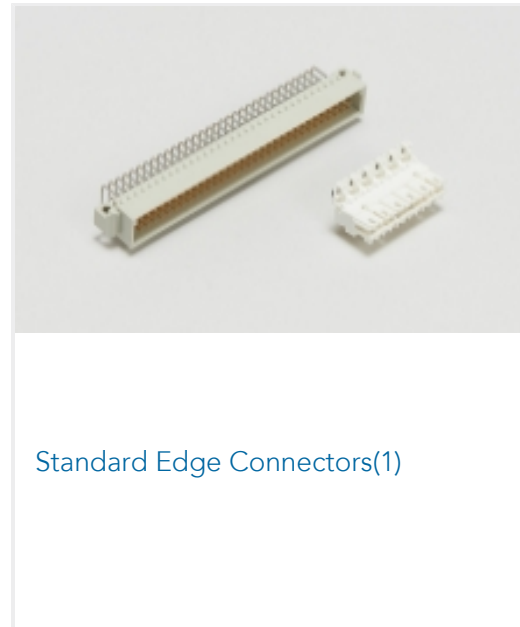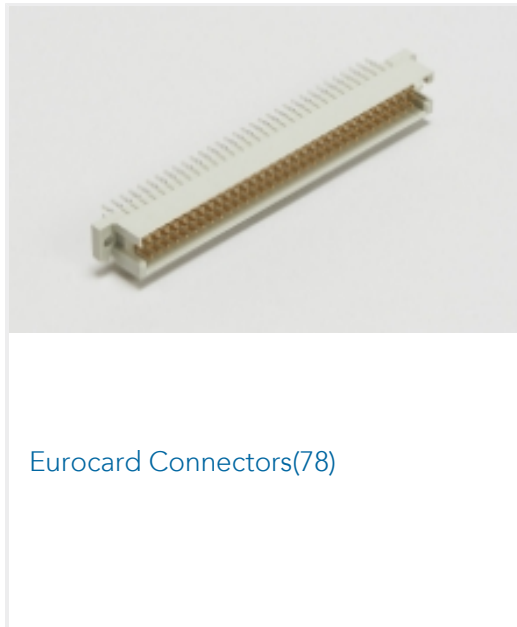

Customers Also Bought





Documents

Product Drawings

[ASSY,PIN,EUROCARD,TYPE R,LEAD-](#)

English

CAD Files

[3D PDF](#)

English

Customer View Model

[ENG_CVM_5650934-5_O.2d_dxf.zip](#)

English

Customer View Model

[ENG_CVM_5650934-5_O.3d_igs.zip](#)

English

Customer View Model

[ENG_CVM_5650934-5_O.3d_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Product Specifications

[Application Specification](#)

English

Agency Approvals

[UL](#)

English