


# Cable Connectors


## Straight Cable Plugs (male)

- > for semi-rigid cables, SUCOFORM and MULTIFLEX cables
- > cable entry soldered
- > centre contact soldered

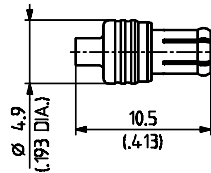

| SUHNER TYPE             | Order No. | Cable Group (example) | Packaging     | Plating Body | Assembly Instruction |
|-------------------------|-----------|-----------------------|---------------|--------------|----------------------|
| 11 MCX-50-1-14 / 111 NE | 23032081  | Y2 (EZ 47)            | single        | SUCOPRO      | 27413                |
| 11 MCX-50-2-19 / 111 NH | 23032147  | Y3, Y11 (EZ 86)       | bulk 100 pcs. | SUCOPRO      | 27496                |


- > for flexible cables
- > SUHNER® full crimp
- > for taper sleeves [CLICK HERE](#)

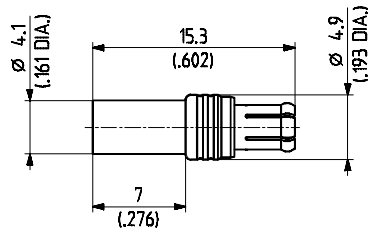

| SUHNER TYPE             | Order No. | Cable Group (example) | Packaging     | Plating Body | Assembly Instruction | Crimp Insert |
|-------------------------|-----------|-----------------------|---------------|--------------|----------------------|--------------|
| 11 MCX-50-1-13 / 133 NH | 22658307  | U1 (EF 178)           | bulk 100 pcs. | SUCOPLATE®   | 27316                | 1 A          |
| 11 MCX-50-1-13 / 111 NH | 23002830  | U1 (EF 178)           | bulk 100 pcs. | gold         | 27316                | 1 A          |
| 11 MCX-50-2-15 / 111 NH | 23000440  | U4 (EF 316 D)         | bulk 100 pcs. | gold         | 27306                | 1 A          |
| 11 MCX-50-2-15 / 133 NH | 23000566  | U4 (EF 316 D)         | bulk 100 pcs. | SUCOPLATE®   | 27306                | 1 A          |
| 11 MCX-50-2-16 / 111 NH | 22658275  | U2 (EF 316)           | bulk 100 pcs. | gold         | 27306                | 1 A          |
| 11 MCX-50-2-16 / 133 NH | 23000437  | U2 (EF 316)           | bulk 100 pcs. | SUCOPLATE®   | 27306                | 1 A          |


# Right Angle Cable Plugs (male)

- > for semi-rigid cables, SUCOFORM and MULTIFLEX cables
- > cable entry soldered
- > centre contact soldered

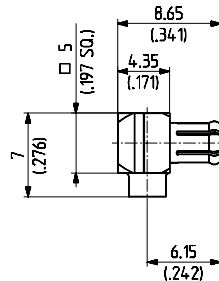


| SUHNER TYPE              | Order No. | Cable Group (example) | Packaging     | Plating Body | Assembly Instruction  |
|--------------------------|-----------|-----------------------|---------------|--------------|-----------------------|
| 16 MCX-50-1-11 / 111 NH  | 23032063  | Y2 (EZ 47)            | bulk 100 pcs. | SUCOPRO      | <a href="#">27495</a> |
| 16 MCX-50-2-104 / 111 NH | 22658277  | Y3, Y11 (EZ 86)       | bulk 100 pcs. | gold         | <a href="#">27308</a> |
| 16 MCX-50-2-104 / 111 NH | 23032067  | Y3, Y11 (EZ 86)       | bulk 100 pcs. | SUCOPRO      | <a href="#">27308</a> |

- > for flexible cables
- > cable entry crimp
- > centre contact soldered
- > for taper sleeves [CLICK HERE](#)

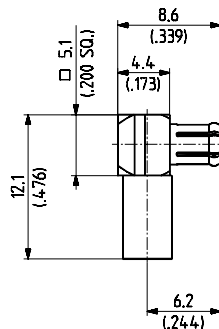

| SUHNER TYPE             | Order No. | Cable Group (example) | Packaging     | Plating Body | Assembly Instruction  | Crimp Insert |
|-------------------------|-----------|-----------------------|---------------|--------------|-----------------------|--------------|
| 16 MCX-50-1-7 / 111 NH  | 23000443  | U1 (EF 178)           | bulk 100 pcs. | gold         | <a href="#">27319</a> | A            |
| 16 MCX-50-1-7 / 133 NH  | 22658308  | U1 (EF 178)           | bulk 100 pcs. | SUCOPLATE®   | <a href="#">27319</a> | A            |
| 16 MCX-50-2-11 / 111 NH | 23000457  | U4 (EF 316 D)         | bulk 100 pcs. | gold         | <a href="#">27102</a> | A            |
| 16 MCX-50-2-11 / 133 NH | 22650803  | U4 (EF 316 D)         | bulk 100 pcs. | SUCOPLATE®   | <a href="#">27102</a> | A            |
| 16 MCX-50-2-14 / 111 NH | 23000445  | U2 (EF 316)           | bulk 100 pcs. | gold         | <a href="#">27102</a> | A            |
| 16 MCX-50-2-14 / 133 NH | 22660001  | U2 (EF 316)           | bulk 100 pcs. | SUCOPLATE®   | <a href="#">27102</a> | A            |


- > for flexible cables
- > low profile
- > cable entry soldered
- > centre contact soldered

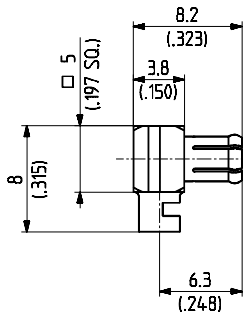

| SUHNER TYPE              | Order No. | Cable Group (example) | Packaging     | Plating Body | Assembly Instruction  |
|--------------------------|-----------|-----------------------|---------------|--------------|-----------------------|
| 16 MCX-50-2-102 / 111 NH | 23000448  | U2 (EF 316)           | bulk 100 pcs. | gold         | <a href="#">27307</a> |
| 16 MCX-50-2-102 / 111 NH | 23000454  | U2 (EF 316)           | bulk 100 pcs. | SUCOPRO      | <a href="#">27307</a> |
| 16 MCX-50-2-102 / 133 NH | 22658276  | U2 (EF 316)           | bulk 100 pcs. | SUCOPLATE®   | <a href="#">27307</a> |

### Straight Cable Jacks (female)

- > for flexible cables
- > SUHNER® full crimp
- > for taper sleeves [CLICK HERE](#)

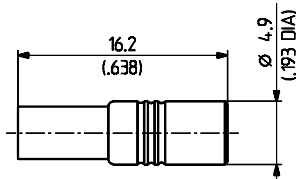

| SUHNER TYPE             | Order No. | Cable Group (example) | Packaging     | Plating Body | Assembly Instruction  | Crimp Insert |
|-------------------------|-----------|-----------------------|---------------|--------------|-----------------------|--------------|
| 21 MCX-50-1-11 / 111 NH | 23005297  | U1 (EF 178)           | bulk 100 pcs. | gold         | <a href="#">27317</a> | 1 A          |
| 21 MCX-50-2-12 / 111 NE | 23032052  | U4 (EF 316 D)         | single        | SUCOPRO      | <a href="#">27309</a> | 1 A          |
| 21 MCX-50-2-12 / 133 NH | 22658278  | U4 (EF 316 D)         | bulk 100 pcs. | SUCOPLATE®   | <a href="#">27309</a> | 1 A          |
| 21 MCX-50-2-13 / 111 NH | 23005298  | U2 (EF 316)           | bulk 100 pcs. | gold         | <a href="#">27309</a> | 1 A          |
| 21 MCX-50-2-13 / 133 NH | 22658279  | U2 (EF 316)           | bulk 100 pcs. | SUCOPLATE®   | <a href="#">27309</a> | 1 A          |

### Straight Bulkhead Cable Jacks (female)

- > for semi-rigid cables, SUCOFORM and MULTIFLEX cables
- > cable entry soldered
- > centre contact soldered

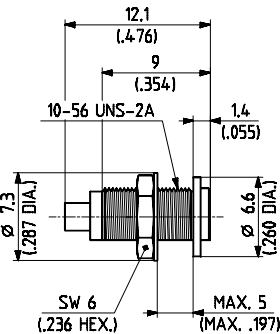


Fig. 1


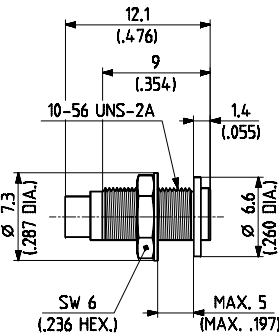


Fig. 2

| SUHNER TYPE            | Order No. | Cable Group (example) | Packaging | Plating Body | Assembly Instruction/<br>Mounting Hole | Fig. |
|------------------------|-----------|-----------------------|-----------|--------------|----------------------------------------|------|
| 24 MCX-50-1-3 / 111 NE | 22641648  | Y2 (EZ 47)            | single    | gold         | 3100 / ML 11                           | 1    |
| 24 MCX-50-2-3 / 111 NE | 22543580  | Y3, Y11 (EZ 86)       | single    | gold         | 3100 / ML 11                           | 2    |

- > for flexible cables
- > SUHNER® full crimp
- > for taper sleeves [CLICK HERE](#)

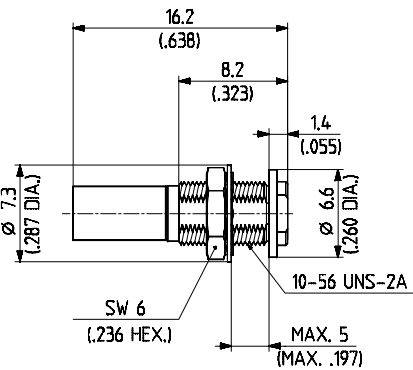

| SUHNER TYPE             | Order No. | Cable Group (example) | Packaging     | Plating Body | Assembly Instruction/<br>Mounting Hole | Crimp<br>Insert |
|-------------------------|-----------|-----------------------|---------------|--------------|----------------------------------------|-----------------|
| 24 MCX-50-1-13 / 111 NH | 23005299  | U1 (EF 178)           | bulk 100 pcs. | gold         | 27317 / ML 11                          | 1 A             |
| 24 MCX-50-1-13 / 133 NH | 22658310  | U1 (EF 178)           | bulk 100 pcs. | SUCOPLATE®   | 27317 / ML 11                          | 1 A             |
| 24 MCX-50-2-6 / 111 NH  | 23005300  | U4 (EF 316 D)         | bulk 100 pcs. | gold         | 27309 / ML 11                          | 1 A             |
| 24 MCX-50-2-7 / 111 NH  | 23000468  | U2 (EF 316)           | bulk 100 pcs. | gold         | 27309 / ML 11                          | 1 A             |

⊠ centre contact NOT captivated