


Part Number : 545520402

Product Description : SlimStack Board-to-Board Receptacle, 0.40mm Pitch, Surface Mount, Dual Row, with Plastic Pegs, 40 Circuits

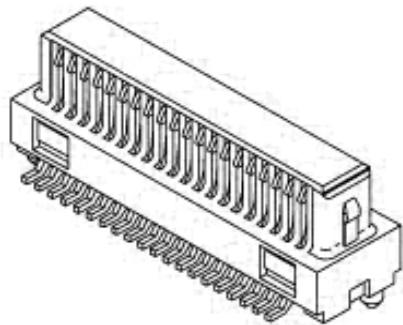

Series Number : 54552

Status : Active

Product Category : Board-to-Board Connectors

Documents & Resources

Drawings

[545520402_sd.pdf](#)

3D Models and Design Files

[STEP AP242](#)

[SOLIDWORKS](#)

[Creo](#)

[Symbol and Footprint \(Multi-Format\)](#)

Specifications

[SPK-54552-017-001.pdf](#)

[PS-54552-023-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Compliant with Exemption 44; 33
China RoHS	per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2025)4165-DC (25 June 2025)
EU RoHS	Compliant per EU 2015/863

Compliance Statements

- EU RoHS

- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	Board-to-Board Connectors
Series	0.4, RA
Description	SlimStack Board-to-Board Receptacle, 0.40mm Pitch, Surface Mount, Dual Row, with Plastic Pegs, 40 Circuits
Application	Board-to-Board, Signal
Component Type	PCB Receptacle
Product Name	SlimStack
UPC	822348830749

Electrical

Current - Maximum per Contact	0.3A
Voltage - Maximum	30V AC (RMS)/DC

Physical

Circuits (Loaded)	40
Circuits (maximum)	40
Color - Resin	Brown
Durability (mating cycles max)	30
Glow-Wire Capable	No

Mated Height	4.25mm, 4.35mm
Material - Metal	Phosphor Bronze
Material - Plating Mating	Gold
Material - Plating Termination	Tin
Net Weight	154.001/mg
Number of Rows	2
Orientation	Vertical
Packaging Type	Embossed Tape on Reel
PCB Locator	Yes
PCB Retention	None
PCB Thickness - Recommended	1.60mm
Pitch - Mating Interface	0.40mm
Pitch - Termination Interface	0.40mm
Polarized to PCB	No
Temperature Range - Operating	-40° to +105°C
Termination Interface Style	Surface Mount

Mates With / Use With

Mates with Part(s)

Description	Part Number
0.40mm Pitch SlimStack Board-to-Board Right-Angle Plugs	<u>503376</u>

This document was generated on Sep 22, 2025