



Ceramic Resonator


Built-in capacitor types

SMD-version
KX-ZTT CV series


part no.	12.99201
model	KX-ZTT-CV MX
frequency	20.0 MHz
internal capacitance C_1, C_2	10 pF
frequency tolerance at +25°C	±0.5 %
frequency stability at -20° ~ +80°C	±0.3 %
aging for 10 years	±0.3 %
resonant resistance max.	40 Ohm
test circuit IC	1/6TC4069UBPx2
contents of reel	1000 pcs.

Please note our Precautions for Handling


Dimensions (mm):

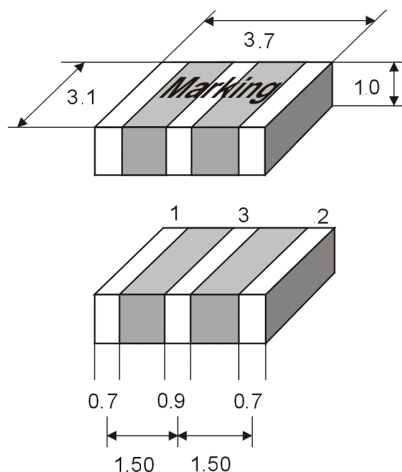


Suggested soldering pad:

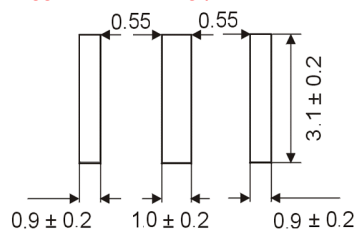

Reflow soldering condition:

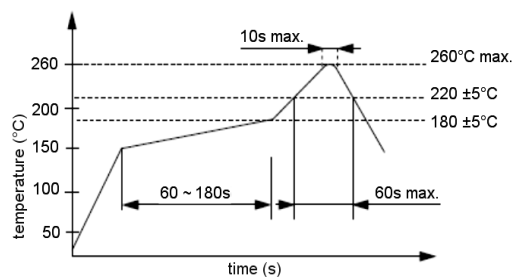

Tape specification:

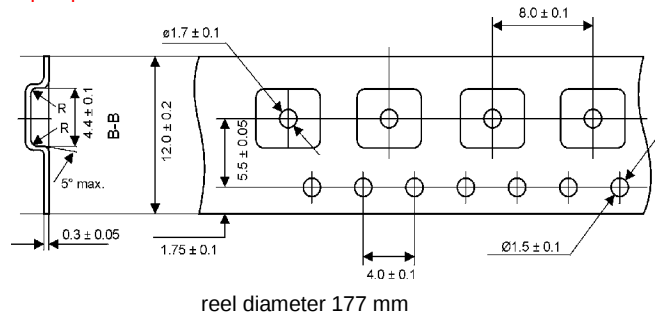

Test circuit:

