

# Incandescent Indicators

TWO TERMINALS – FULLY INSULATED

MEET OR EXCEED ENVIRONMENTAL AND OPERATIONAL REQUIREMENTS  
OF MIL-L-6723 AND MIL-L-3661B



T-1 3/4  
MIDGET  
FLANGE BASE

See lamp ratings  
on page J.

For materials and finishes of products  
in this group, see preceding page.

101 SERIES  
108 SERIES  
109 SERIES  
111 SERIES  
112 SERIES  
134 SERIES  
140 SERIES

## Features

- Available for mounting FRONT or BACK of panel in 15/32" or 1/2" clearance hole; also from FRONT of panel in 15/32" or 17/32" clearance hole.
- Rugged-phenolic insulated: The socket, lamp and all connections are well insulated from the mounting bushing by means of phenolic material of military specification grade.
- Lens cap assembly unscrews from front of panel for easy replacement of the lamp. Indicators on Pages 10C – 11C have friction-fit lens caps which are also easily removed from front of panel.
- Two terminals (soldering) are provided for electrical connections.

## COLORED LEGENDS

### 134 SERIES FLAT LENS ONLY



**Colored Legends on black or gray lenses:** Legends can also be furnished in "negative" or "reverse" style. That is, the legend is illuminated in white or other color while the background remains opaque black or gray. To specify black or gray lens, change the first two digits of the code block preceding the last dash in the catalog number. To obtain black lens, use "57"; to obtain gray lens, use "58".  
Examples: 134-3830-5752-201 (black);  
134-5030-5875-201 (gray)

- Specify translucent colors as follows: Red-0351...Green-0352...  
Yellow (amber) -0373...Blue-0374...White-0375...Light Yellow-0376

### How to designate the Three Digit Part Number Suffix (-XXX)

| Finish              | Resistor | Hardware                         |
|---------------------|----------|----------------------------------|
| 1 – white nickel    | 0 – none | 1 – brass                        |
| 2 – black nickel    |          | 3 – water tight on face of panel |
| 3 – polished chrome |          |                                  |

Example: 101-3830-0931-201 (Black nickel finish, no resistor, brass hardware)  
101-3830-0931-203 (same, water tight)

### Lens Colors

|                  |                     |
|------------------|---------------------|
| 1-Red            | 5-White translucent |
| 2-Green*         | 6-Light yellow      |
| 3-Yellow (amber) | 7-Clear colorless   |
| 4-Blue*          |                     |

\*Not recommended with Neon Glow Lamps.

The digit before the last dash in the part number designates the lens color. When color other than red is desired, change this digit to a figure noted above. Example: 101-5030-0936-201


Part numbers listed in this catalog designate products with RED lens. For ordering lens colors other than red, consult chart above.

Order complete with lamp to be assured of receiving the indicator light and correct lamp together for immediate use.


Part numbers shown in gray are normally in inventory at your Dialight Distributor.

## BASE PART NUMBERS

### CAP PART NUMBERS

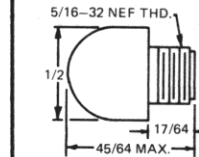


**STOVEPIPE**  
101-0931  
transparent  
101-0971  
translucent

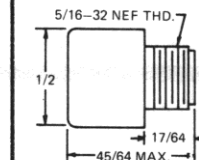


**CYLINDRICAL**  
140-1431  
transparent  
140-1471  
translucent


For legends on flat faced lens, see page P.

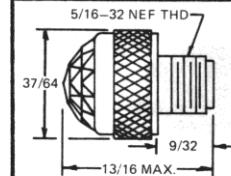

**FACETED**  
134-2131-200  
unfrosted

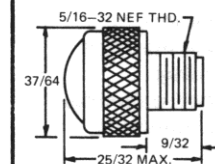


**CONVEX**  
134-0131-200  
unfrosted  
134-0111-200  
back frosted

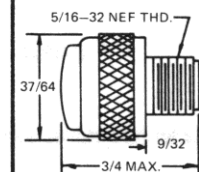


**ROTATABLE LENS  
FLAT**  
134-0331-200  
transparent  
134-0351-200  
translucent

For legends on flat faced lens, see page P.

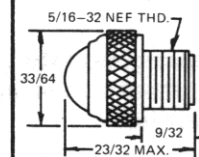

**NON-DIMMING TYPES  
CONVEX**  
111-0131-200  
unfrosted  
111-0111-200  
back frosted

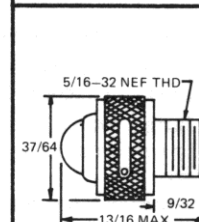

**DIMMER TYPES  
CONVEX**  
**Complete Blackout**  
108-0131-200  
unfrosted  
108-0111-200  
back frosted  
**Semi-Blackout**  
109-0131-200  
unfrosted  
109-0111-200  
back frosted  
**Polaroid**  
112-0131-200  
unfrosted  
112-0111-200  
back frosted

|                                                                                 |                                                                       |                                                                       |
|---------------------------------------------------------------------------------|-----------------------------------------------------------------------|-----------------------------------------------------------------------|
| <p><b>FRONT OR BACK MOUNTING with MOVABLE FLANGE</b></p> <p>101-3830-09-201</p> | <p><b>FRONT MOUNTING with FIXED FLANGE</b></p> <p>101-5030-09-201</p> | <p><b>FRONT MOUNTING with FIXED FLANGE</b></p> <p>101-8430-09-201</p> |
|---------------------------------------------------------------------------------|-----------------------------------------------------------------------|-----------------------------------------------------------------------|

**COMPLETE ASSEMBLY PART NUMBERS**

|                                                                                                                                              |                                                                                                                                              |                                                                                                                                              |
|----------------------------------------------------------------------------------------------------------------------------------------------|----------------------------------------------------------------------------------------------------------------------------------------------|----------------------------------------------------------------------------------------------------------------------------------------------|
| <p>101-3830-0931-201<br/>101-3830-0971-201</p>                                                                                               | <p>101-5030-0931-201<br/>101-5030-0971-201</p>                                                                                               | <p>101-8430-0931-201<br/>101-8430-0971-201</p>                                                                                               |
| <p>140-3830-1431-201<br/>140-3830-1471-201</p>                                                                                               | <p>140-5030-1431-201<br/>140-5030-1471-201</p>                                                                                               | <p>140-8430-1431-201<br/>140-8430-1471-201</p>                                                                                               |
| <p>134-3830-2131-201</p> <p>134-3830-0131-201<br/>134-3830-0111-201</p> <p>134-3830-0331-201<br/>■ 134-3830-0351-201</p>                     | <p>134-5030-2131-201</p> <p>134-5030-0131-201<br/>134-5030-0111-201</p> <p>134-5030-0331-201<br/>■ 134-5030-0351-201</p>                     | <p>134-8430-2131-201</p> <p>134-8430-0131-201<br/>134-8430-0111-201</p> <p>134-8430-0331-201<br/>■ 134-8430-0351-201</p>                     |
| <p>111-3830-0131-201<br/>111-3830-0111-201</p>                                                                                               | <p>111-5030-0131-201<br/>111-5030-0111-201</p>                                                                                               | <p>111-8430-0131-201<br/>111-8430-0111-201</p>                                                                                               |
| <p>108-3830-0131-201<br/>108-3830-0111-201</p> <p>109-3830-0131-201<br/>109-3830-0111-201</p> <p>112-3830-0131-201<br/>112-3830-0111-201</p> | <p>108-5030-0131-201<br/>108-5030-0111-201</p> <p>109-5030-0131-201<br/>109-5030-0111-201</p> <p>112-5030-0131-201<br/>112-5030-0111-201</p> | <p>108-8430-0131-201<br/>108-8430-0111-201</p> <p>109-8430-0131-201<br/>109-8430-0111-201</p> <p>112-8430-0131-201<br/>112-8430-0111-201</p> |