




Color: white

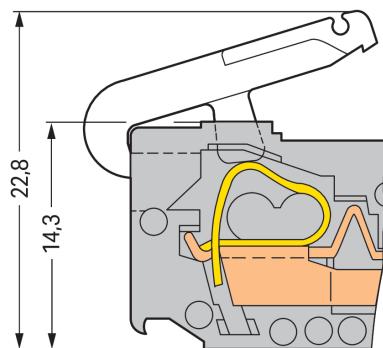

Dimensions in mm

Operating levers are not suitable for panel-mount, angled female connectors.

Technical data

Number of spacings	1 -times
--------------------	----------

Physical data

Depth	20.2 mm / 0.79 inches
Pin spacing	5/7.62 mm

Mechanical data

Suitable	for male and female connectors with CAGE CLAMP® connection
----------	--

Material data

Color	white
Material group	I
Insulation material (main housing)	Glass fiber-reinforced polyamide (PA66 GF)
Flammability class per UL94	HB
Fire load	0.01 MJ
Weight	0.3 g

Commercial data

Product Group	3 (Multi Conn. System)
PU (SPU)	100 (25) pcs
Packaging type	Box
Country of origin	DE
GTIN	4017332283168
Customs tariff number	82055980000

Product Classification

UNSPSC	27111701
eCl@ss 10.0	27-14-11-92
eCl@ss 9.0	27-14-11-92
ETIM 9.0	EC002848
ETIM 8.0	EC002848
ECCN	NO US CLASSIFICATION

Environmental Product Compliance

RoHS Compliance Status	Compliant, No Exemption
------------------------	-------------------------

Processing temperature (min.) -35 °C

Processing temperature (max.) 60 °C

Approvals / Certificates**General approvals**

Approval	Standard	Certificate Name	Approval	Standard	Certificate Name
CSA DEKRA Certification B.V.	C22.2	1466354	LR Lloyds Register	IEC 61984	96/20035 (E5)

**Downloads****Environmental Product Compliance**

Compliance Search

Environmental Product
Compliance 231-131**CAD/CAE-Data**

CAD data

2D/3D Models 231-131

CAE data

ZUKEN Portal 231-131

**Installation Notes**Inserting a conductor into CAGE CLAMP®
unit via operating tool (231-291).

Subject to changes. Please also observe the further product documentation!

Current addresses can be found at: www.wago.com