


Part Number : 153660167

Product Description : 0.50mm Pitch Premo-Flex FFC Jumper, Same Side Contacts (Type A), 102.00mm Cable Length, Tin (Sn) Plating, 16 Circuits, with Shield

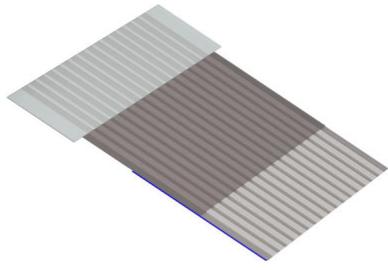

Series Number : 15366

Status : Active

Product Category : Flat-Flexible Cable (FFC)

Documents & Resources

Drawings

153660167_sd.pdf

STEP AP242

SOLIDWORKS

Creo

Specifications

153660001-000.pdf

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	ⓘ per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Not Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2024)7663-DC (21 Jan 2025)
EU RoHS	Compliant per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	Flat-Flexible Cable (FFC)
Series	15366
Description	0.50mm Pitch Premo-Flex FFC Jumper, Same Side Contacts (Type A), 102.00mm Cable Length, Tin (Sn) Plating, 16 Circuits, with Shield
Product Name	Premo-Flex FFC Jumper
UPC	193264621996

Electrical

Current - Maximum per Contact	0.5A
Voltage - Maximum	N/A

Physical

Cable Length	102.00mm
Circuits (Loaded)	16
Contact Layout Type	A (same side)
Design Feature	EMI Protection
Material - Plating Mating	Tin
Packaging Type	Bag
Pitch - Mating Interface	0.50mm
Temperature Range - Operating	-40° to +105°C
Termination Style	FFC Connector

Wire/Cable Type	Flat Flex Cable
Wire Size (AWG)	N/A

Mates With / Use With

Mates with Part(s)

Description	Part Number
Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Vertical, 3.90mm Height, 16 Circuits, Tin-Bismuth Plating	<u>525591672</u>
Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Vertical, 3.90mm Height, 16 Circuits, Tin-Bismuth Plating	<u>525591670</u>
Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Right-Angle, Top Contact, 2.00mm Height, 16 Circuits, Tin-Bismuth	<u>527451696</u>
Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Right-Angle, Bottom Contact, 2.00mm Height, 16 Circuits, Tin-Bismuth Plating	<u>527461670</u>
0.50mm Pitch Easy-On FFC/FPC Connector, Surface Mount, Vertical, Non-ZIF, Standard Footprint, Tin Bismuth Plating, Short Terminal Type, Black, 16 Circuits	<u>781191610</u>
0.50mm Pitch Easy-On FFC/FPC Connector, Surface Mount, Vertical, Non-ZIF, Reverse Footprint, Tin Bismuth Plating, Long Terminal Type, Black, 16 Circuits	<u>781271610</u>

This document was generated on Sep 16, 2025