



Electrical Commercial and Industrial


[Products](#) | [Documentation & Literature](#) | [News & Tradeshows](#) | [Support](#) |

United States > All 3M Products > Market Segments > Electronics, Electrical, and Communications > Electrical Products > Electrical Commercial and Industrial > Products > Electrical Commercial & Industrial Products Catalog > Terminals, Kits and Tools > Terminals > 3M™ Scotchlok™ Piggy-Back Disconnects > 3M™ Scotchlok™ Multi-Stack Disconnect, Vinyl Insulated Butted Seam MVU18-250DMFK-A

[Find An Account Rep](#) [Where To Buy \(Find A Distributor\)](#) [Contact Us](#)

3M™ Scotchlok™ Multi-Stack Disconnect, Vinyl Insulated Butted Seam MVU18-250DMFK-A


3M ID 80611444078 UPC# 00051138980627 3M Product Number MVU18-250DMFK-A

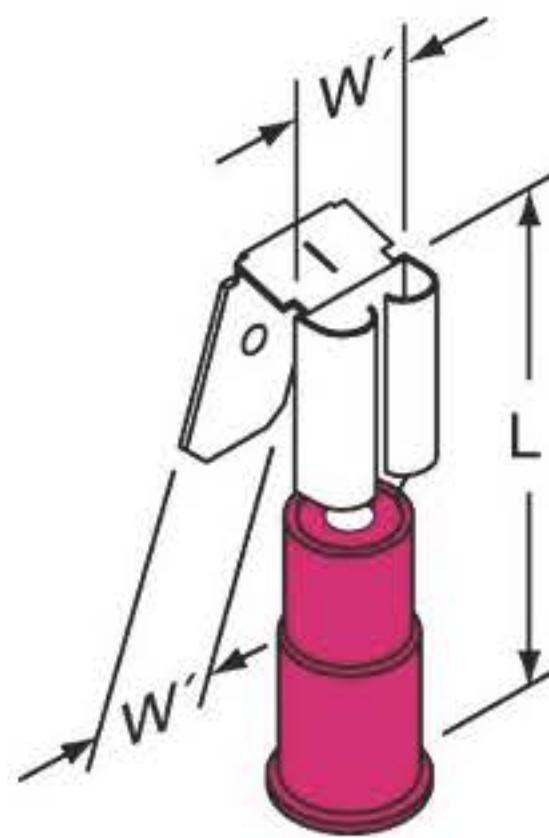[Print](#)[Share](#)

3M™ Scotchlok™ Multi-Stack Disconnects - Vinyl Insulated Butted Seam, MVU18-250DMFK-A, 22-18 AWG

Need Help?

Questions? We can help
[Contact Us](#)

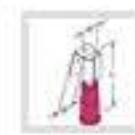

[Like](#) Sign Up to see what your friends like..

[Overview](#) [Documentation](#)**Specifications**

Barrel Inside Diameter	0.07 Inch
Barrel Length	0.23 Inch
Barrel Style	Butted
Brand	Scotchlok
China RoHS - Below MCV	Yes
Conductor Sizes	22 - 18 AWG
EU RoHS Compliant	Yes
Fastener Orientation	Male-Female
Insulation Material	Vinyl
Length (L)	0.87 Inch
Mates with Male Tab Width (W')	0.25 Inch
Maximum Insulation Outer Diameter	0.145 Inch
Packaging	1000 per bulk box
Pad Width	0.250 Inch
Terminal Style	Piggy-back
Terminal Type	Disconnect
Thickness	0.032 Inch