


284932-5 Product Details

 Share

 Print

 Email

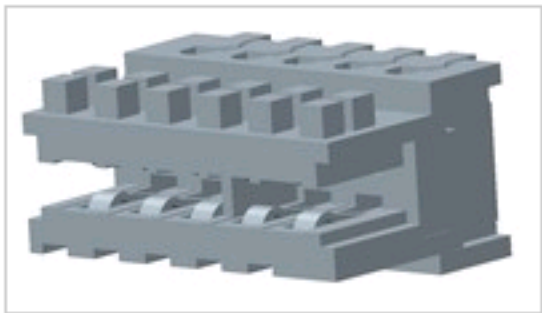

 Active

 View 3D PDF

2.5mm & 5mm Centerline Connector System (AMP DUOPLUG)

DUOPLUG STD FEMALE CONN., 5 POS.

284932-5 

TE Internal Number: 284932-5

Product Highlights [View All](#)

- Connector
- 2.50 mm Centerline
- Connector Assembly
- Connector Style = Receptacle
- Contact Type = Socket

Pricing & Availability



Request Sample



Add to My Part List



Buy Product through Distributor



 Feedback

Documents

Features

Compliance

Please Note:

Use the Product Drawing for all design activity



Product Type Features	
Product Type	Connector
Connector Type	Connector Assembly
Wire/Cable Type	Stranded
Wire Size (mm² [AWG])	0.22-0.35² [24-22]
Wire Insulation Diameter (mm [in])	1.27 [0.050]
Color	Black
Termination Features	
Termination Method to Wire/Cable	Insulation Displacement Crimp (IDC)
Body Features	
Selectively Loaded	No
Keying Between Cavity Number(s)	2/3
Contact Features	
Contact Type	Socket
Contact Base Material	Phosphor Bronze
Contact Plating, Mating Area, Material	Tin
Housing Features	
Centerline (mm [in])	2.50 [0.098]
Connector Style	Receptacle
Housing Material	PBT GF

Configuration Features	
Number of Positions 	5
Industry Standards	
RoHS/ELV Compliance 	RoHS compliant, ELV compliant
Lead Free Solder Processes 	Not relevant for lead free process
RoHS/ELV Compliance History	Always was RoHS compliant
UL Flammability Rating	UL 94V-0
Conditions for Usage	
Applies To 	Wire/Cable
For Use With	Header, PCB Frame
Operation/Application	
Industry Application	Appliances
Packaging Features	
Packaging Quantity	280
Other	
Brand	AMP

Related Products

Not quite the product you're looking for?

[Find Similar Products](#)

[View Part in Product Feature Selector](#)

[Check for Tooling](#)