


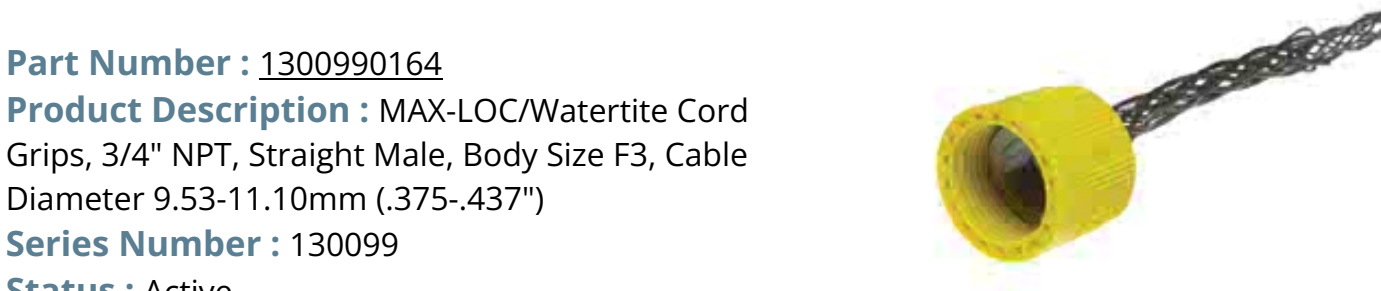

Part Number : [1300990164](#)
Product Description : MAX-LOC/Watertite Cord Grips, 3/4" NPT, Straight Male, Body Size F3, Cable Diameter 9.53-11.10mm (.375-.437")
Series Number : 130099
Status : Active
Product Category : Cable Grips
Engineering Number : 5628M



Documents & Resources

Drawings

[1300990164 sd.pdf](#)

Product Environment Compliance

Compliance

| | |
|--------------------|--------------|
| China RoHS | Not Reviewed |
| EU ELV | Not Reviewed |
| Low-Halogen Status | Not Reviewed |
| REACH SVHC | Not Reviewed |
| EU RoHS | Not Reviewed |

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Part Details

General

| | |
|--------------|--|
| Status | Active |
| Category | Cable Grips |
| Series | 130099 |
| Description | MAX-LOC/Watertite Cord Grips, 3/4" NPT, Straight Male, Body Size F3, Cable Diameter 9.53-11.10mm (.375-.437") |
| NEMA Rating | NEMA 3R |
| Product Name | MAX-LOC,Watertite |
| Type | Strain Relief Grip |
| UPC | 78678841495 |

Physical

| | |
|----------------------------|---------------------------|
| Approximate Break Strength | N/A |
| Bale Length | N/A |
| Body Style | Straight |
| Cable Diameter | 9.53-11.10mm (.375-.437") |
| Color - Grommet | Green |
| Eye Type | N/A |
| Gender | Male |
| Material - Body | Nylon |
| Material - Grip | Stainless Steel |
| Mesh Length | N/A |
| Number of Holes | 1 |
| O-Ring | N/A |
| Thread Size | 3/4" NPT |

Mates With / Use With

Use with Part(s)

| | |
|---------------------------|-------------------|
| Description | Part Number |
| MAX-LOC Lock Nut 3/4" NPT | <u>1300990144</u> |

| | |
|---|-------------------|
| MAX-LOC Gasket Sealing Ring, 3/4" NPT, Black | <u>1300990150</u> |
| MAX-LOC O-Ring, 3/4" NPT | <u>1301800333</u> |

This document was generated on Sep 10, 2025