


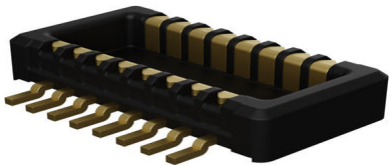

Part Number : [555600168](#)
Product Description : 0.50mm Pitch SlimStack Plug,
Surface Mount, Dual Row, Vertical, 1.50mm Stack
Height, 16 Circuits
Series Number : 55560
Status : Active
Product Category : Board-to-Board Connectors



Documents and Resources

Drawings

[555600168 sd.pdf](#)
[SPK-55560-002-001.pdf](#)

3D Models and Design Files

[STEP AP242](#)
[SOLIDWORKS](#)
[Creo](#)
[Symbol and Footprint \(Multi-Format\)](#)
[555600168.dxf](#)

Specifications

[547220000-A00.pdf](#)
[PS-54722-010-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2025)7771-DC (04 Feb 2026)
EU RoHS	Compliant per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	Board-to-Board Connectors
Series	0.5, BB H1.5
Description	0.50mm Pitch SlimStack Plug, Surface Mount, Dual Row, Vertical, 1.50mm Stack Height, 16 Circuits
Application	Board-to-Board
Component Type	Plug
Product Name	SlimStack
UPC	800755985405

Agency

UL	E29179
----	--------

Electrical

Current - Maximum per Contact	0.5A
Voltage - Maximum	50V

Physical

Breakaway	No
Circuits (Loaded)	16
Circuits (maximum)	16
First Mate / Last Break	No
Flammability	94V-0
Glow-Wire Capable	No
Guide to Mating Part	No
Keying to Mating Part	No
Lock to Mating Part	Yes
Mated Height	1.50mm
Mated Width	6.00mm
Material - Metal	Brass
Material - Plating Mating	Gold
Material - Plating Termination	Gold
Net Weight	24.344/mg
Number of Rows	2
Orientation	Vertical
Packaging Type	Embossed Tape on Reel
PCB Locator	No
PCB Retention	No
PC Tail Length	0.74mm
Pitch - Mating Interface	0.50mm
Plating min - Mating	0.254µm
Plating min - Termination	0.102µm
Shrouded	Shrouded
Temperature Range - Operating	-40° to +105°C
Termination Interface Style	Surface Mount

Mates With / Use With

Mates with Part(s)

Description	Part Number
0.50mm Pitch Vertical SlimStack Receptacles	<u>54722</u>

This document was generated on May 22, 2026