



TOP VIEW

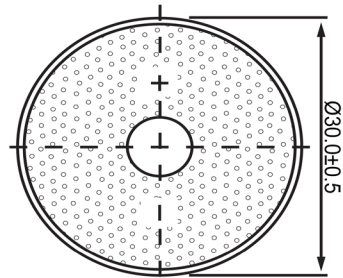

SIDE VIEW

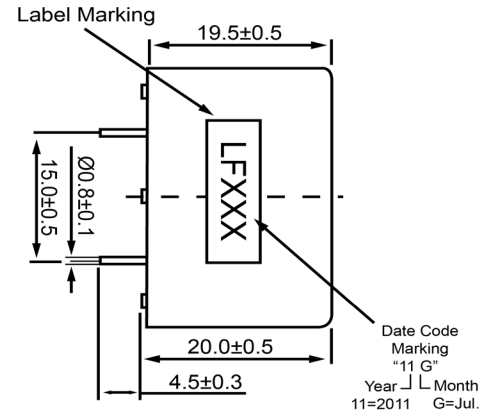

Specifications			Notes	Revision History								
Description	Value	Unit		Version	Description		Date	Approved				
Technology	Piezo		1) All dimensions are in mm unless otherwise noted 2) All parts meet RoHS	1	Released from Engineering		10/21/2013	J.S				
Resonant Frequency	3,500	(Hz)										
Rated Voltage	12	(V)										
SPL @ 10cm	100	(dBA)										
Tone	Single											
Mount Type	Thru-hole											
Voltage Range	3 ~ 20	(V)										
Max Rated Current	10	(mA)										
Housing Material	PBT											
Operating Temperature	-20 ~ +60	°C										
Storage Temperature	-20 ~ +60	°C										
Weight	10	(g)										
 DB UNLIMITED						Drawn by		Date	Checked by	Date	Approved by	Date
						A.B.		10/21/2013	C.E.	10/21/2013	J.S	10/21/2013
						Piezo Indicator			IP303512-1			