
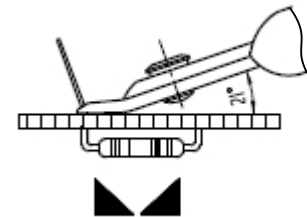


A

 
B

C

D

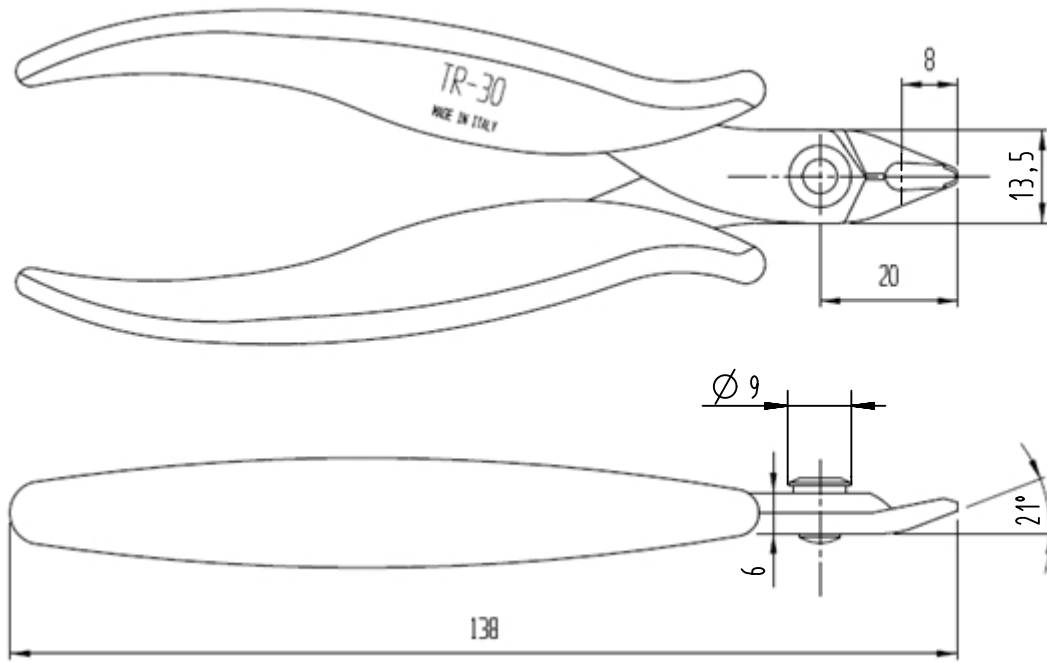

- Cutting edges angled 21°, especially for use in the electronic production, easy handling because of little weight
- Lap-Joint with spring
- Tight-fit joint movement
- Specially heat treated (temper 54-56° HRC)
- Carbon-steel C70 finely punched

Coating		A=	mm ²	V=	mm ³	m=	g	Mat. INELCO p/n 061-501				
		All Dimensions in mm Original Size DIN A4		Scale 1: 1		Free size tol.			Ref.			
									Sub. TB 09 45 800 0005 03.05.10			
	All rights reserved		Created by HASSE		Inspected by LINDKAMP		Standardisation HOFFMANN		Date 2013-01-22		State Final Release	
	Department EC PD - DE											
HARTING Electronics GmbH D-32339 Espelkamp		Title HARTING RJ Industrial Wire cutter								Doc-Key / ECM-Nr. 100527066/UGD/001/A 500000058428		
		Type TB	Number 09458000005						Rev. A	Page 1/1		