


P	LTR	DESCRIPTION	DATE	DWN	APVD
	A	NEW DRAWING	31SEP2020	GK	DB

PRESENTATION

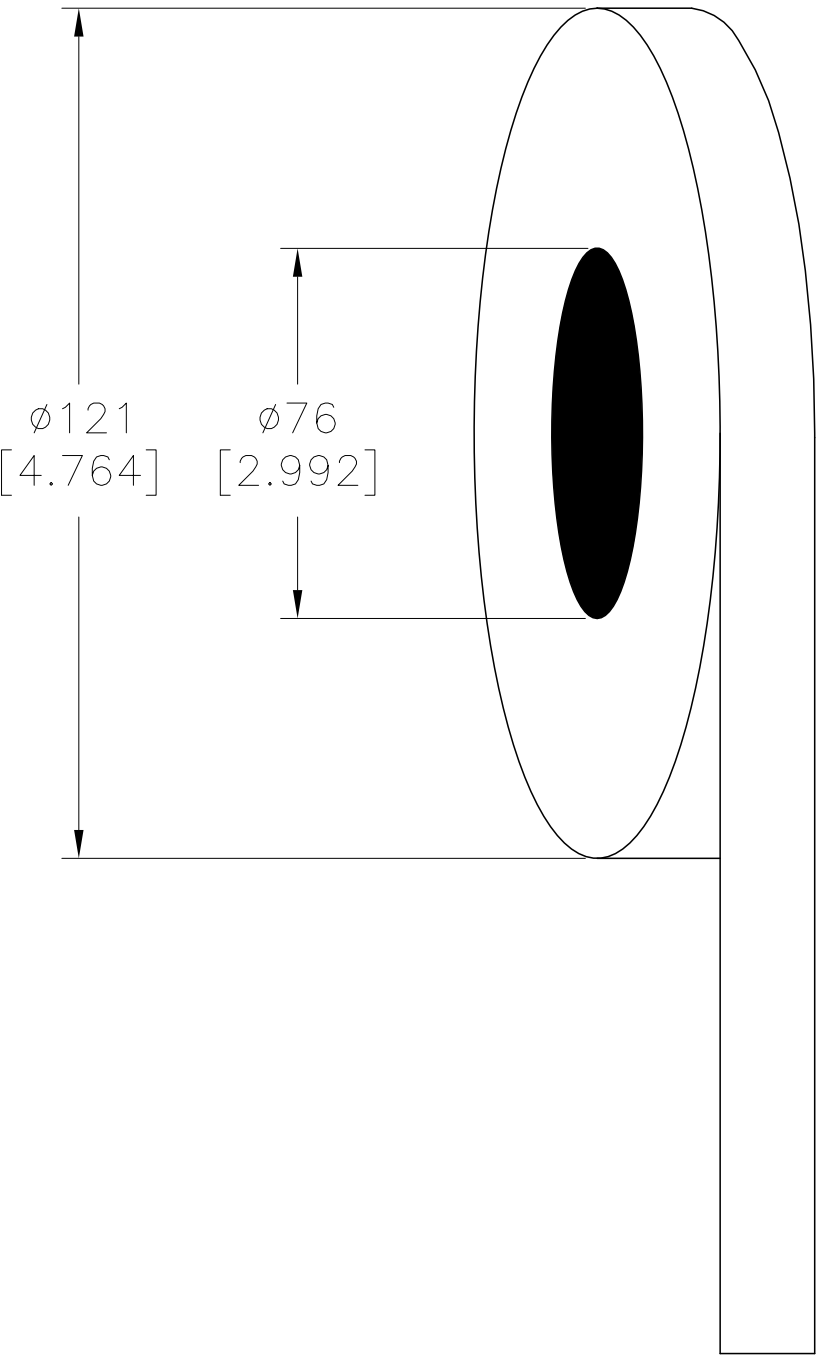

OUTSIDE WOUND
LABEL ACROSS: 1
PER ROLL QTY: 30.48m / 100 feet

MATERIAL	POLYVINYL FLUORIDE (TEDLAR®)
ADHESIVE TYPE	PERMANENT ACRYLIC
LINEAR	BROWN KRAFT

TOLERANCES mm [INCH]		THIS DRAWING IS A CONTROLLED DOCUMENT.		DWN 31SEP2020 GOPALAKRISHNA HV CHK 31SEP2020 D.BURGAT APVD 31SEP2020 D.BURGAT PRODUCT SPEC TTDS-004 APPLICATION SPEC —		 TE Connectivity	
LABEL HEIGHT: ±0.3 [0.12]	DIMENSIONS: mm [INCHES] 	TOLERANCES UNLESS OTHERWISE SPECIFIED: 0 PLC ± — 1 PLC ± — 2 PLC ± — 3 PLC ± — 4 PLC ± — ANGLES ± —		NAME		TEDLAR® LABEL — WHITE — CONTINUOUS	
LABEL WIDTH: ±0.3 [0.12]						12.7mm x 30.4m (0.5inch x 100ft)	
WEB WIDTH: ±0.8 [0.31]						—	
VERTICAL REPEAT: ±0.8 [0.31]*							
HORIZONTAL REPEAT: ±0.8 [0.31]*				SIZE	CAGE CODE	DRAWING NO	RESTRICTED TO
PRINT POSITIONING: ±0.8 [0.31]*				—	—	—	—
LEFT MARGIN: ±0.4 [0.16]	MATERIAL	FINISH	WEIGHT	A2	FB1U7	C-NPVF050WE-100	—
QUANTITY: -0 % +2 %	SEE TABLE	GLOSS	53 g	CUSTOMER DRAWING		SCALE NTS	SHEET 1 of 1
*NON ACCUMULATING							REV A