




- Home
- Products
- Online Catalog
- Request Quote
- Order Online
- Check Stock
- Request Print Catalog
- Request Samples
- Engineering Data
- Distributors
- Capabilities Brochure

CALL NOW:
203 888-2133



Home > 5/16 Hex Female Standoffs

5/16 HEX FEMALE STANDOFFS

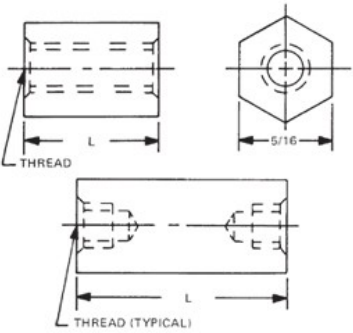

Qty1 *

Qty2

Qty3

☐	2190	1-11/16
☐	2191	1-3/4
☐	2192	1-13/16
☐	2193	1-7/8
☐	2194	1-15/16
☒	2195	2
☐	2196	2-1/8
☐	2197	2-1/4
☐	2198	2-3/8
☐	2199	2-1/2
☐	2200	2-5/8
☐	2201	2-3/4
☐	2202	2-7/8

Thread *		
Select	Code	Thread
☐	440	4-40
☐	632	6-32
☐	832	8-32
☒	1032	10-32

Material *			
Select	Code	Material	RoHS
☒	AL	Aluminum	YES
☐	B	Brass	YES
☐	SS	Stainless Steel	YES
☐	S	Steel	YES
☐	N	Nylon	YES

Finish *	
☒	Plain Finish
☐	1-Cad clear chromate/commercial*
☐	2-Cad clear chromate*
☐	3-Cad yellow chromate*
☐	4-Chrome over nickel
☐	5-Nickel
☐	6-Gold iridite*
☐	7-Clear iridite
☐	9-Alodine 1200*
☐	10-Bright chrome
☐	11-Satin chrome

[Home](#) [Previous](#) [Next](#)
[Related Metric](#)

Ordering Code			
xxxxx	xxx	xx	x
Length	Thread	Material	Finish

PART: 2195 1032 AL

Red ?'s show missing selections. [Help](#)

- [Thread depth information](#)
- [Material Specifications](#)
- [Ordering non-standard items](#)
- [Download a Drawing](#)

Add to Cart

