


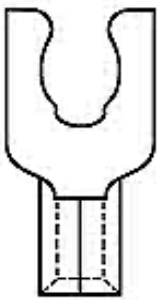

Part Number : [190980050](#)
Product Description : Krimptite Snap Spade Tongue
Terminal for 16-14 AWG Wire, Stud Size 10 (M5),
Length 17.63mm, Mylar Tape Carrier
Series Number : 19098
Status : Active
Product Category : Ring and Spade Terminals
Engineering Number : BB-1717-10T



Documents & Resources

Drawings

[190980050 sd.pdf](#)

3D Models and Design Files

[STEP AP242](#)

[SOLIDWORKS](#)

[Creo](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2025)4165-DC (25 June 2025)
EU RoHS	Compliant per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C

- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	Ring and Spade Terminals
Series	19098
Description	Krimptite Snap Spade Tongue Terminal for 16-14 AWG Wire, Stud Size 10 (M5), Length 17.63mm, Mylar Tape Carrier
Keyword	Spade Terminal, Spade Terminals
Product Name	Krimptite
Style	Spade Snap
Type	Spade Connector, Metric Spade Connector
UPC	800753088320

Agency

CSA	LR18689
UL	E32244

Physical

Barrel Type	Closed
Insulation	None
Material - Plating Mating	Tin
Net Weight	0.689/g
Packaging Type	Adhesive Tape on Reel
Stud Size	10 (M5)

Wire Size (AWG)	14, 16
Wire Size mm ²	1.00-2.50

Application Tooling

Global

Description	Part Number
ATP Crimp Dies for the Tape Crimp Module and ATP-101 & 301 Press	<u>190270068</u>
Mini-Mac Applicator, Air Feed Mylar Tape	<u>638853900</u>

This document was generated on Sep 24, 2025