


Part Number : [5041931300](#)

Product Description : Micro-Lock 1.25mm Pitch Single-Row Crimp Housing, White, 13 Circuits, 5041931300

Series Number : 504193

Status : New Business Not Supported


Product Category : Connector Housings

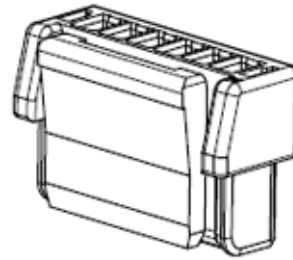

Documents & Resources

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Not Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2024)4144-DC (27 June 2024)
EU RoHS	Compliant per EU 2015/863

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	New Business Not Supported
Category	Connector Housings
Series	504193
Description	Micro-Lock 1.25mm Pitch Single-Row Crimp Housing, White, 13 Circuits, 5041931300
Application	Wire-to-Board
Product Family	Micro-Lock Connector System
Product Name	Micro-Lock
UPC	887191165318

Physical

Circuits (maximum)	13
Color - Resin	White
Gender	Receptacle
Glow-Wire Capable	No
Lock to Mating Part	Yes
Material - Resin	Polyester
Net Weight	219.572/mg
Number of Rows	1
Packaging Type	Tray
Panel Mount	No
Pitch - Mating Interface	1.25mm
Pitch - Termination Interface	1.25mm
Polarized to Mating Part	Yes
Temperature Range - Operating	-25° to +85°C

This document was generated on Oct 01, 2024