
 


5mm x 20mm FUSE HOLDERS

SLIM LINE

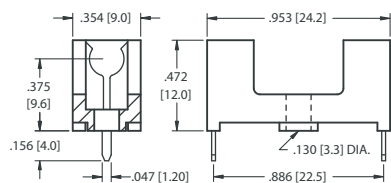

Mounting Detail




SPECIFICATIONS

Base & Cover: Nylon,
UL Rated 94V-0
Clips: Brass, Tin Plate
Rated: 5 Amps @ 250V AC


CAT. NO. 4628 - Holder

CAT. NO. 4628C - Cover only (with window)

LOW PROFILE

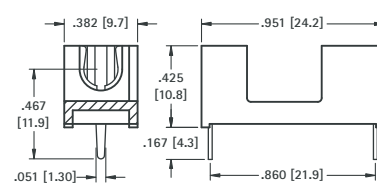

Mounting Detail

 


SPECIFICATIONS

Base & Cover: Nylon,
UL Rated 94V-0
Clips: Brass, Tin Plate
Rated: 5 Amps @ 250V AC


CAT. NO. 4527 - Holder

CAT. NO. 4527C - Cover only

FULLY INSULATED

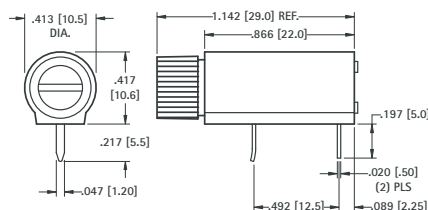

Mounting Detail


 


SPECIFICATIONS


Base: PBT
Contacts: Brass, Tin Plate
Rated: 10 Amps @ 250V AC

CAT. NO. 4525

PC SNAP-IN

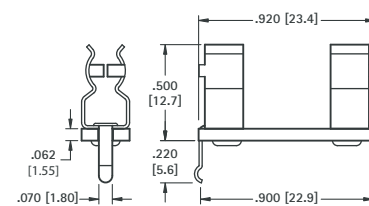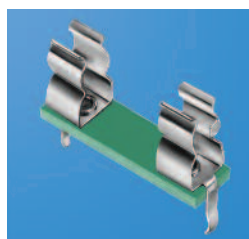

Mounting Detail

 

SPECIFICATIONS


Base: .062 (1.57) FR-4, UL Rated 94V-0
Clips: Brass, Tin Plate
UL Rated: 6.3 Amps @ 250V AC

CAT. NO. 3527 - Holder


3AG FUSE HOLDERS



TERMINATION LUGS CAN BE USED WITH WIRES OR PC MOUNT

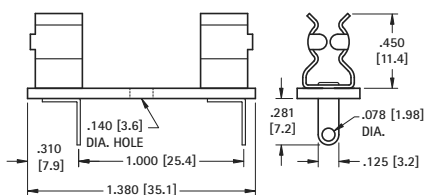

Mounting Detail

 


SPECIFICATIONS

Base: .062 (1.57) FR-4, UL Rated 94V-0
Clips: Brass, Tin Plate
UL Rated: 15 Amps @ 500VAC


CAT. NO. 3526

Optional cover available - Cat. No. 4245C

PRESS-FIT, IDEAL FOR WAVE SOLDERING

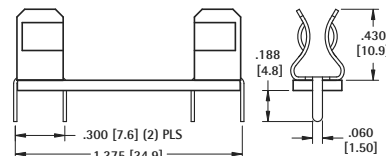

Mounting Detail

 


SPECIFICATIONS

Base: .062 (1.57) FR-4, UL Rated 94V-0
Clips: Brass, Tin Plate
UL Rated: 15 Amps @ 500VAC


CAT. NO. 4245

Optional cover available - Cat. No. 4245C

SNAP-IN DESIGN ASSURES STABILITY DURING WAVE SOLDERING

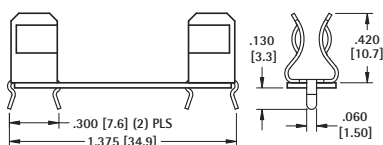

Mounting Detail

 


SPECIFICATIONS

Base: .032 (.79) FR-4, UL Rated 94V-0
Clips: Brass, Tin Plate
UL Rated: 15 Amps @ 500VAC

CAT. NO. 4250

Optional cover available - Cat. No. 4245C

MOLDED CASE

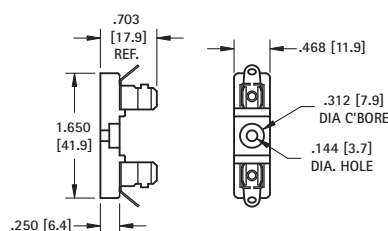

SPECIFICATIONS

Base: LCP, UL Rated 94V-0
Clips: Brass - Nickel Plated
UL Rated: 15 Amps @ 250 VAC

CAT. NO. 3523

Optional cover available - Cat. No. 4245C

Mounting Hole:
.144 (3.7) Dia.