

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1552200241

Status:


Active

Overview:

Flamar Standard and Custom Cables for Industrial Automation

Description:

Flamar Control Cable, WSOR Jacket, Unshielded, 7 Circuits, 1.50mm² with Green-Yellow Ground / 16 AWG with Green-Yellow Ground, 10.50mm (.413") Diameter, 100.0m (328.08') Length, Black

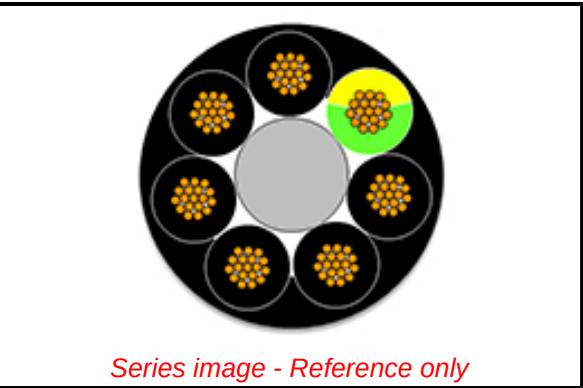

Series image - Reference only

Documents:

Product Specification 1552200001-P1E (PDF)

RoHS Certificate of Compliance (PDF)

Brochure (PDF)

Agency Certification	
UL	E172949
General	
Product Family	Cable
Series	155220
Crimp Quality Equipment	Yes
Geographic Area	Global
Overview	Flamar Standard and Custom Cables for Industrial Automation
Product Name	Flamar, Signal and Control
Taxonomy	Industrial Cable
UPC	889056461450
Physical	
Bending Radius - Minimum	> 7.5xOD
Cable Length	100.0m
Circuits (Loaded)	7
Color - Cable Jacket	Black
Insulation	TPE
Material - Outer Jacket	WSOR
Net Weight	0.174/kg
Outer Jacket Diameter	10.50mm
Packaging Type	Reel
Temperature Range - Operating	-25° to +80°C
Wire Size AWG	16
Wire Size mm²	1.50
Wire/Cable Type	UL AWM 21215 / CSA
Electrical	
Current - Maximum per Contact	Contact Molex
Voltage - Maximum	600V
Material Info	
Engineering Number	1X100M
Reference - Drawing Numbers	
Product Specification	1552200001-P1E

EU ELV

Not Relevant

EU RoHS

China RoHS

Compliant

REACH SVHC

Not Contained per -

D(2022)4187-DC (10

June 2022)

Halogen-Free

Status

Not Reviewed

For more information, please visit

Contact US

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

155220 Series

Use With

DIN Valve Connectors 121201 , 121202 , 121207 , 121208 , 121205 , 121211
Micro-Change (M12) 120071
Ultra-Lock (M12) 120085
GWconnect Heavy Duty Connectors 93601

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION