



TE Connectivity: Every Connection Counts
© 2017 TE Connectivity Ltd. family of companies. All Rights Reserved

+ HARNESSING

HEAT SHRINK BOOTS

TE CONNECTIVITY (TE)

202D232-4-61/42-0-CS5077

Raychem

202D232-4-61/42-0-CS5077

TE Internal Number: 779193N001

Mil-Spec: **MS3109-03AC**

Alias ID: 2-1196064-6

EU RoHS Compliant

EU ELV Compliant

Molded Part Shape **Straight**

Lipped **Yes**

Operating Temperature Range (°C) **-20 – 60**

Fluid/Chemical Resistance **Suitable for occasional exposure to fluids**

Adhesive Options **/42 Precoat, -20 – 60°C (-4 – 140°F)**

✓ Active

↓ **PRODUCT DRAWING**
English

Product Drawings

Boot, Straight, With Lip

PDF **(TIFF AVAILABLE)**

English

Product Specifications

Product Specification

Thermofit Polyolefin Molded Components Flame-Retarded, Flexible, Heat-Shrinkable

PDF
English

Harnessing Customer Specification Report

PDF
English

Product Environmental Compliance

Safety Data Sheet

Thermofit Heat-Shrinkable Polymeric Products

PDF
English

Thermofit Heat-Shrinkable Polymeric Products

PDF
Danish

Thermofit Heat-Shrinkable Polymeric Products

PDF
Dutch

Thermofit Heat-Shrinkable Polymeric Products

PDF
English

Thermofit Heat-Shrinkable Polymeric Products

PDF
French

Thermofit Heat-Shrinkable Polymeric Products

PDF
German

Thermofit Heat-Shrinkable Polymeric Products



Thermofit Heat-Shrinkable Polymeric Products

PDF

Italian

Thermofit Heat-Shrinkable Polymeric Products

PDF

Norwegian

Thermofit Heat-Shrinkable Polymeric Products

PDF

Spanish

Thermofit Heat-Shrinkable Polymeric Products

PDF

Swedish

Thermofit Heat-Shrinkable Polymeric Products

PDF

Spanish

Aliphatic Polyamide Based Adhesives.

PDF

Dutch

Aliphatic Polyamide Based Adhesives.

PDF

English

Aliphatic Polyamide Based Adhesives.

PDF

French

Aliphatic Polyamide Based Adhesives.

PDF

German

Aliphatic Polyamide Based Adhesives.

PDF

Italian



Aliphatic Polyamide Based Adhesives.

PDF

Spanish

Aliphatic Polyamide Based Adhesives.

PDF

Swedish

Thermofit Heat-Shrinkable Polymeric Products

PDF

English

Thermofit Heat-Shrinkable Polymeric Products

PDF

English

Aliphatic Polyamide Based Adhesives.

PDF

English



Please review product documents or [contact us](#) for the latest agency approval information. Please Note: Use the Product Drawing for all design activity.

Product Type Features

Molded Part Type

Molded Boot

Molded Part Shape

Straight

Configuration Features

Lipped

Yes

Body Features

Material Systems Code

10

Adhesive Pre-Coat

Yes

Dimensions

Connector or Backshell Outside Diameter

.87 in, .94 in, 1.02 in, 1.1 in, 22 mm, 24 mm, 26 mm, 28 mm

Wire/Cable Outside Diameter

.39 in, .43 in, .47 in, .55 in, .63 in, 10 mm, 11 mm, 12 mm, 14 mm, 16 mm

Usage Conditions

Operating Temperature Range (°C)

-20 – 60

Industry Standards

Approved Standards

SAE AS I 81765/1, Type II, UL 224, File E85381

Other

Fluid/Chemical Resistance

Suitable for occasional exposure to fluids

Adhesive Options

/42 Precoat, -20 – 60°C (-4 – 140°F)

Statement of Compliance

[Statement of Compliance](#)


 
PDF

Compatible Products

> [Contact Product Support](#)

Customers Also Bought

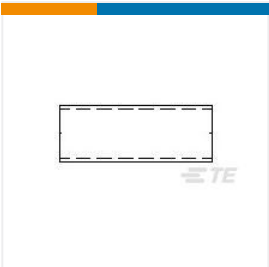

RF CONNECTORS	HEAT SHRINK TUBING	HEAT SHRINK BOOTS	CONVOLUTED TUBING
			
TNC PLUG DUAL W/P 225550-2	RT-1145-OX-12-0 RT-1145-OX-12-0	202D132-4-60-0-CS5077 202D132-4-60-0-CS5077	HCTE-1250-0-SP 7730454002